

LOW-VOLTAGE HEADS

Tellium Head

DESCRIPTION

Simple, industrial-inspired head puts light where you need it. Machined aluminum and brass housings create crisp edges. Head rotates 360°; pivots 90° to direct the beam. Integrated lens holder accommodates up to two lenses or louvers (sold separately). Accepts low-voltage, MR16 lamp of up to 50 watts (not included).

INSTALLATION


Socket terminates with FreeJack male connector, which may be installed into a system connector. Elements ordered with a system prefix include a connector for that system.

ACCESSORIES & OPTICAL CONTROLS

Colored Lens, Dichroic Lens, Diffuser Lens, Eggcrate Louver, Linear Spread Lens, Soft Focus Lens, UV Filter

WEIGHT

1.03lb / 0.47kg ±

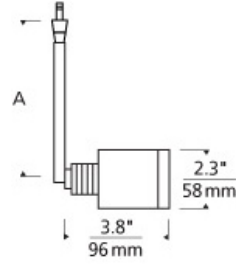

tellium head

ORDERING INFORMATION

700 SYSTEM	TLM	LENGTH (A)	FINISH
FJ	FREEJACK	03 3"	Z ANTIQUE BRONZE
MP	MONOPOINT	06 6"	S SATIN NICKEL
MO	MONORAIL	12 12"	
MO2	TWO-CIRCUIT MONORAIL	18 18"	

Note: MP includes 4" Round Flush Canopy.



TECH LIGHTING®
 7400 Linder Avenue T 847.410.4400
 Skokie, Illinois 60077 F 847.410.4500
Tech Lighting, L.L.C.

700 ____ TLM ____ ____

FIXTURE TYPE: _____

JOB NAME: _____

NOTES: _____



©2016 Tech Lighting, L.L.C. All Rights Reserved. The "Tech Lighting" graphic is a registered trademark of Tech Lighting, L.L.C. Tech Lighting reserves the right to change specifications for product improvements without notification.