

Square steel poles with welded tenon included for use with floodlights. Designed for ground mounting. Poles are stocked nationwide for quick shipment. Protective packaging ensures poles arrive at the job site good as new.

Color: Bronze

Weight: 319.0 lbs

Project:

Type:

Prepared By:

Date:

#### Lamp Info

Type: N/A  
 Watts: 0W  
 Shape/Size: N/A  
 Base: N/A  
 ANSI: N/A  
 Hours: N/A  
 Lamp Lumens: N/A  
 Efficacy: N/A

#### Ballast Info

Type: N/A  
 120V: N/A  
 208V: N/A  
 240V: N/A  
 277V: N/A  
 Input Watts: 0W

## Technical Specifications

### Listings

#### CSA Listed:

Suitable for wet locations.

### Construction

#### Shaft:

46,000 p.s.i. minimum yield.

#### Hand Holes:

Reinforced with grounding lug and removable cover.

#### Base Plates:

36,000 p.s.i. minimum yield.

#### Shipping Protection:

All poles are shipped in individual corrugated cartons to prevent finish damage.

#### Color:

Bronze powder coating.

#### Height:

25 FT.

#### Gauge:

7

#### Wall Thickness:

3/16"

#### Shaft Size:

5"

#### Hand Hole Dimensions:

3" x 5"

#### Bolt Circle:

11"

#### Base Dimension:

11"

#### Weight:

319 lbs.

#### Anchor Bolt:

Galvanized anchor bolts and galvanized hardware and anchor bolt template. All bolts have a 3" hook.

#### Anchor Bolt Templates:

WARNING Template must be printed on 11" x 17" sheet for actual size. CHECK SCALE BEFORE USING. Templates shipped with anchor bolts and available .

#### Pre-Shipped Anchor Bolts:

Bolts can be pre-shipped upon request for additional freight charge.

#### MaxEPA's/Max Weights:

70MPH 19.6 ft./450 lb  
 80MPH 13.9 ft./320 lb  
 90MPH 9.8 ft./225 lb  
 100MPH 6.7 ft./155 lb  
 110MPH 4.4 ft./100 lb  
 120MPH 2.6 ft./60 lb  
 130MPH 1.2 ft./25 lb.

### Other


#### Terms of Sale:

Pole Terms of Sale is available .

#### Buy American Act Compliance:

RAB values USA manufacturing! Upon request, RAB may be able to manufacture this product to be compliant with the Buy American Act (BAA). Please contact customer service to request a quote for the product to be made BAA compliant.

## Dimensions

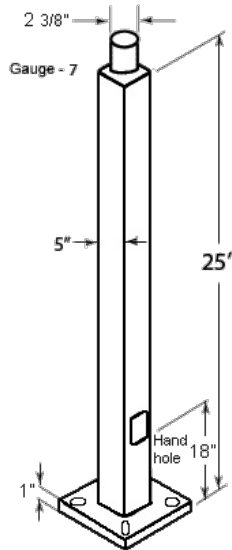

## Features

- Designed for ground mounting
- Heavy duty TGIC polyester coating
- Reinforced hand holes with grounding lug and removable cover for easy wiring access
- Anchor Bolt Kit includes pole cap and base cover (sold separately)
- Custom manufactured for each application