


Thermocouple

- Measures up to 1500° F (816° C)
- K-type thermocouple plugs into digital multimeter voltage jacks with 61-465 adapter

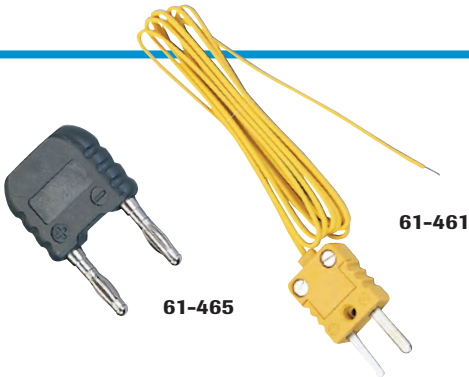

Description	Cat. No.
Beaded K-type Thermocouple	61-461
Thermocouple Adapter	61-465

Carrying Cases



Description	Cat. No.
Leather Carrying Case - for use with 61-065, 61-076, 61-085, 61-086	61-010
Small Nylon Carrying Case w/four pockets	61-445
Nylon Carrying Case - for use with all Vol-Con® and Vol-Test® Voltage Testers	C-90
Nylon Carrying Case - for use with Digital Multimeters	C-290

Carrying Case Selection Guide

		VOLTAGE TESTERS								160	310	340	360	480	490	610	700	740	760	770	830									
		61-059	61-065	61-076	61-085	61-086	61-090	61-092	61-096	61-164	61-165	61-310	61-312	61-340	61-342	61-361	61-484	61-486	61-497	61-498	61-610	61-614	61-702	61-704	61-744	61-746	61-763	61-765	61-773	61-775
61-179	Nylon Carrying Case								•	•																				•
C-50	Nylon Carrying Case	•																												
C-90	Nylon Carrying Case		•	•	•	•	•	•																•	•					
C-230	Nylon Carrying Case																	•	•											
C-290	Nylon Carrying Case										•	•	•	•	•	•	•	•	•	•	•									
C-700	Nylon Carrying Case																					•	•							
C-760	Nylon Carrying Case																									•	•			
C-770	Nylon Carrying Case																											•	•	