

DESCRIPTION

693 Series LED Trims – 6-inch Aperture Micro Step Baffles - are integral elements in the Halo ML56 LED Downlighting System. ML56 LED System is a series of modular LED Light Modules for use with dedicated 5" or 6" ML56 LED trims. The ML56 LED trims in 5" and 6" aperture sizes are designed to fit Halo, All-Pro and others 5" or 6" recessed housings. The ML56 system is suitable for new construction, remodel or retrofit installation.

Catalog #		Type
Project		
Comments		Date
Prepared by		

SPECIFICATION FEATURES

693 Series LED trims are 6-inch aperture micro-step baffles offered in White (Matte White), Black, Satin Nickel, and Tuscan Bronze. The white and black baffles feature matte white finish flange, the Satin Nickel baffle a Satin Nickel flange, and the Tuscan Bronze baffle a Tuscan Bronze flange. The precision spun aluminum micro-step baffle delivers the functionality of a baffle in reduced aperture brightness, as well as excellent optical performance. The 693 baffles may be used in most standard height 6-inch aperture recessed housings; Halo, All-Pro, and more (refer to ML56 LED Light Module specifications for details).

- For use with ML56 Series LED light modules
- For use in standard housings
- Baffles with self-flange
- Wet location shower listed with ML56 LED Light Modules
- Torsion springs pull trim and light module tight to ceiling
- ML56 downlight trims and modules make any housing AIR-TITE™ (ASTM E283)

Compatible with ML56 LED System of LED Downlight Light Modules

600 Series - 80CRI, 600lm

5" / 6" LED Retrofit Downlight Engine

ML5606827 - 2700K
ML5606830 - 3000K
ML5606835 - 3500K
ML5606840 - 4000K

600 Series - 90CRI, 600lm

5" / 6" LED Retrofit Downlight Engine

ML5606927 - 2700K
ML5606930 - 3000K
ML5606935 - 3500K
ML5606940 - 4000K

900 Series - 80CRI, 900lm

5" / 6" LED Retrofit Downlight Engine

ML5609827 - 2700K
ML5609830 - 3000K
ML5609835 - 3500K
ML5609840 - 4000K

900 Series - 90CRI, 900lm

5" / 6" LED Retrofit Downlight Engine

ML5609927 - 2700K
ML5609930 - 3000K
ML5609935 - 3500K
ML5609940 - 4000K

1200 Series - 80CRI, 1200lm


5" / 6" LED Retrofit Downlight Engine

ML5612827 - 2700K
ML5612830 - 3000K
ML5612835 - 3500K
ML5612840 - 4000K

1200 Series - 90CRI, 1200lm

5" / 6" LED Retrofit Downlight Engine

ML5612927 - 2700K
ML5612930 - 3000K
ML5612935 - 3500K
ML5612940 - 4000K

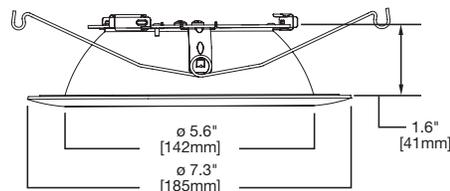

693WB



693BB



693SNB



693TBZB

693 Series LED Trim

6-Inch Micro-Step Baffle

For use with Halo ML56 LED System Light Modules

ORDERING INFORMATION

SAMPLE NUMBER: 693WB

Trim	Finish	Accessory
693= 6" Micro-Step Baffle	WB =White Baffle, White Flange BB =Black Baffle, White Flange SNB =Satin Nickel Baffle, Satin Nickel Flange TBZB =Tuscan Bronze Baffle, Tuscan Bronze Flange	TRM690WH =6" LED Oversize Trim Ring for use with 69" series trims, White 6.9" I.D., 9.5" O.D. Ring slips over LED trim. Inset design allows 6" trim to fit into oversize ring for an even trim surface ML56CLIP = Friction Clip Mounting Kit - For retrofitting non-torsion spring housings, 6" clips