


# NT-5001

## Baffle Splay Trim with Flange

### DIMENSIONS

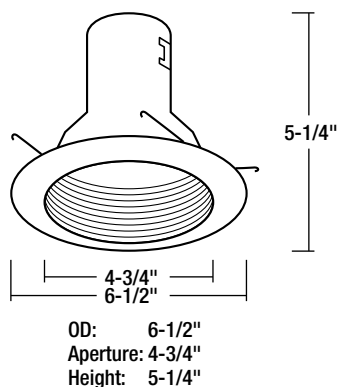

### FEATURES

#### Trim

Precision spun high grade reflector and baffle with deep grooves to reduce aperture glare.

#### Mounting

Trim includes two "V" torsion springs to mount trim securely to housing. Replacement "V" torsion springs are available (NRA-86). Remove socket from socket plate within housing (if applicable), and mount socket in trim's neck.

#### Compatible Housings

Compatible with Line Voltage, Compact Fluorescent, and GU24 housings. See individual specification sheets for more information.

#### Lamp

##### Line Voltage

75W BR30/PAR30 (NH-501Q; NHIC-501QAT; NHR-504Q; NHRIC-504QAT)

**Note:** 50W BR30/PAR30 when used with NT-5001MW

##### Compact Fluorescent

13W-26W Quad/Triple (NHP-501 Series; NHPIC-5 Series; NHRP-504 Series; NHRPIC-5 Series)

##### GU24 Compact Fluorescent

13W-26W GU24 (NHIC-5G24ATFL, NHRIC-5G24ATFL)

#### Labels and Listings

cULus Listed for Damp Location when used with Compatible Housings

### Baffle Splay Trim with Flange

**NT-5001B:** Black Aluminum Baffle with White Flange

**NT-5001BZ:** Bronze Aluminum Baffle with Bronze Flange

**NT-5001CO:** Copper Aluminum Baffle with Copper Flange

**NT-5001MW:** White Metal Baffle Splay with White Flange

**NT-5001N:** Natural Metal Aluminum Baffle Splay with Natural Metal Flange

**NT-5001W:** White Aluminum Baffle Splay with White Flange

**NORALIGHTING.**

Type

Project

Catalog No.

Lamp/Wattage

### Compatible Housings

LINE VOLTAGE			
Item Number	Installation Type	Lamp	Dimensions
<b>NH-501Q</b>	Non-IC New Construction	75W BR/PAR30	W: 7-1/4" L: 10-1/2" H: 7-1/2"
<b>NHIC-501QAT</b>	IC Air-Tight New Construction	75W BR/PAR30	W: 7-1/4" L: 10-1/2" H: 7-1/2"
<b>NHR-504Q</b>	Non-IC Remodel Housing	75W BR/PAR30	W: 5-1/2" L: 13-1/2" H: 7-1/2"
<b>NHRIC-504QAT</b>	IC Air-Tight Remodel Housing	75W BR/PAR30	W: 5-1/2" L: 13-1/2" H: 7-1/2"
COMPACT FLUORESCENT			
<b>NHP-501/13</b>	Non-IC New Construction	13W 2-Pin Quad	W: 7-3/8" L: 11-1/2" H: 7-1/2"
<b>NHP-501/13EL</b>	Non-IC New Construction	13W Quad/Triple	W: 7-3/8" L: 10-1/2" H: 7-1/2"
<b>NHP-501/18EL</b>	Non-IC New Construction	18W Quad/Triple	W: 7-3/8" L: 10-1/2" H: 7-1/2"
<b>NHPIC-501QAT13</b>	IC Air-Tight New Construction	13W 2-Pin Quad	W: 7-3/8" L: 11-1/2" H: 7-1/2"
<b>NHPIC-513ELAT</b>	IC Air-Tight New Construction	13W Quad/Triple	W: 7-3/8" L: 10-1/2" H: 7-1/2"
<b>NHPIC-513ATE2</b>	IC Air-Tight New Construction	13W Quad/Triple	W: 7-3/8" L: 10-1/2" H: 7-1/2"
<b>NHPIC-518ELAT</b>	IC Air-Tight New Construction	18W Quad/Triple	W: 7-3/8" L: 10-1/2" H: 7-1/2"
<b>NHPIC-518ATE2</b>	IC Air-Tight New Construction	18W Quad/Triple	W: 7-3/8" L: 10-1/2" H: 7-1/2"
<b>NHPIC-526ELAT</b>	IC Air-Tight New Construction	26W Quad/Triple	W: 7-3/8" L: 10-1/2" H: 7-1/2"
<b>NHPIC-526ATE2</b>	IC Air-Tight New Construction	26W Quad/Triple	W: 7-3/8" L: 10-1/2" H: 7-1/2"
<b>NHRP-504/13</b>	Non-IC Remodel Housing	13W 2-Pin Quad	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRP-504/13EL</b>	Non-IC Remodel Housing	13W Quad/Triple	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRP-504/18EL</b>	Non-IC Remodel Housing	18W Quad/Triple	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRPIC-504QAT13</b>	IC Air-Tight Remodel Housing	13W 2-Pin Quad	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRPIC-513ELAT</b>	IC Air-Tight Remodel Housing	13W Quad/Triple	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRPIC-513ATE2</b>	IC Air-Tight Remodel Housing	13W Quad/Triple	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRPIC-518ELAT</b>	IC Air-Tight Remodel Housing	18W Quad/Triple	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRPIC-518ATE2</b>	IC Air-Tight Remodel Housing	18W Quad/Triple	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRPIC-526ELAT</b>	IC Air-Tight Remodel Housing	26W Quad/Triple	W: 6-1/4" L: 13" H: 7-1/2"
<b>NHRPIC-526ATE2</b>	IC Air-Tight Remodel Housing	26W Quad/Triple	W: 6-1/4" L: 13" H: 7-1/2"
GU24 COMPACT FLUORESCENT			
<b>NHIC-5G24ATFL</b>	IC Air-Tight New Construction	13W-26W GU24	W: 7-1/4" L: 10-1/2" H: 7-1/2"
<b>NHRIC-5G24ATFL</b>	IC Air-Tight Remodel Housing	13W-26W GU24	W: 6-1/4" L: 13" H: 7-1/2"

**NORALIGHTING.**

6505 Gayhart St., Commerce, CA 90040  
www.noralighting.com • Specifications subject to change without notice. © 2011  
Phone: 800.686.6672 • FAX: 800.500.9955 • e-mail: nora@noralighting.com