

3 LED with Bracket
15745AZT27 (Textured Architectural Bronze)

Project Name: _____
Location: _____
Type: _____
Qty: _____
Comments: _____

Ordering Information

Product ID	15745AZT27
Finish	Textured Architectural Bronze
Available Finishes	AZT, BBR, GRY, SD, WHT, CO, AZT, BBR, CO, GRY, SSD, WHT

Dimensions

Weight	0.55 LBS
--------	----------

Photometrics

Kelvin Temperature	2560K
--------------------	-------

Specifications

Material	Aluminum
----------	----------

Electrical


Voltage	12VAC/VDC
Operating Voltage Range	9-15 VAC/VDC

Qualifications

Safety Rated	Wet
Expected Life Span	40000 Hours
Warranty	www.kichler.com/warranty

Primary Lamping

Light Source	LED
Lamp Included	Integrated
Number of Lights/LEDs	3
Max or Nominal Watt	.81W

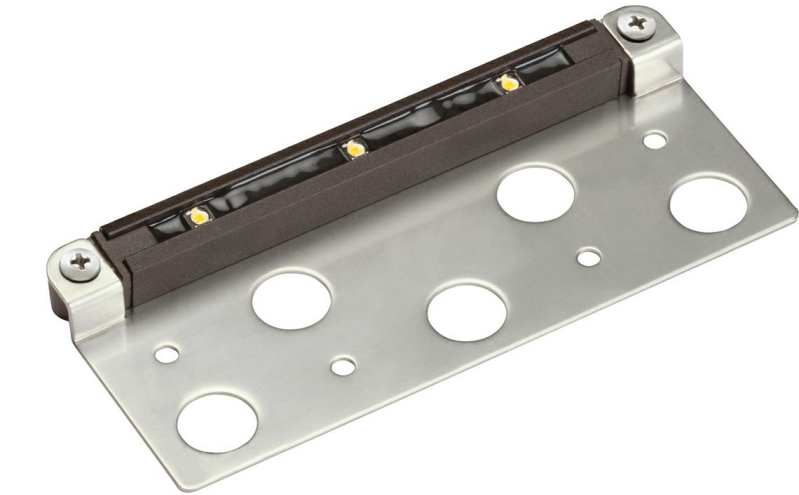

Dimensions

Height	0.75"
Length	7.00"
Width	3.00"