




On Line Catalog

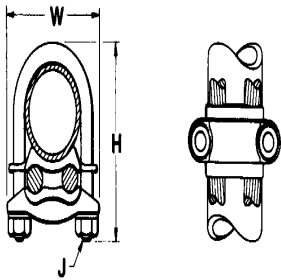

BURNDY Catalog Number GD2029
 UPC Number 781810260395
 Description 2/0SOL-250, 3 IPS, 2 CO
 Status Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 4.81
 Height (in) 5.625
 Size (Hex) or Size (Bolt) 3/8
 Size (Hex) or Size (Bolt) - in 0.38
 Width (Fraction) 4-7/8
 Height (Fraction) (in) 5-5/8

General

Product Description Mechanical Grounding Connector,
 2 Parallel Cables to Rod or Pipe,
 2/0 AWG (Sol.) - 250 kcmil, 3" to
 3-1/2" Rod, 3" Pipe

Conductor(s)

Copper Tube Size (SCH40) - Range 3
 Rod Size (Range) N/A
 Copper Solid Size (Range) 2/0-4/0
 Copper Stranded (Range) 2/0-250

Physical

Installation Torque 240
 Type of Plating Unplated
 Plated (Yes or No) N
 Product Material Copper Alloy

Approvals / Certifications

UL Listed Y
 CSA Certified N
 ROHS Compatible Exempt
 UL Recognized N
 CULUS N
 Industry Standards UL467
 Rated for Direct Burial Y
 Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Services

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM
 Monday - Friday
 Phone: 000-346-4175

