

Gland type:

- Non-armored

Cable type:

- Non-armored and tray cable

Features:


- Weatherproof seal on outer sheath of cable
- Standard neoprene seal suitable for use in operating temperatures -25°C to 40°C
- Available with NPT threads

Certifications and compliances:

- Suitable for use in Class I, Division 2 hazardous locations when installed in accordance with NEC501.10(B)(2)

Standard material:

- Form B-C bodies and gland nuts – turned steel
- Form D-G bodies and gland nuts – Feraloy iron alloy

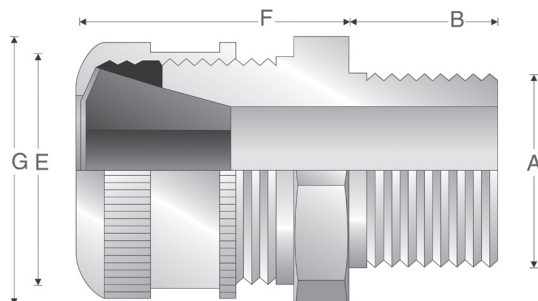

Ordering information:

Entry thread size (A)			Cable acceptance outer sheath (E)				Cat. # Neoprene bushing 80°C
NPT thread size	Cat. #	Form	NPT thread length (B)	Min.	Max.	Gland length less entry (F)	
1/2"	CGFP192	B	0.750	0.125	0.250	1.375	BUSH92
1/2"	CGFP193	B	0.750	0.250	0.375	1.375	BUSH93
1/2"	CGFP194	B	0.750	0.375	0.500	1.375	BUSH94
1/2"	CGFP195	B	0.750	0.500	0.625	1.375	BUSH05
3/4"	CGFP296	C	0.750	0.625	0.750	1.750	BUSH239
3/4"	CGFP297	C	0.750	0.750	0.875	1.750	BUSH96
3/4"	CGFP2239	C	0.750	0.875	1.000	1.750	BUSH96
1"	CGFP396	C	0.938	0.625	0.750	1.750	BUSH239
1"	CGFP397	C	0.938	0.750	0.875	1.750	BUSH96
1"	CGFP3239	C	0.938	0.875	1.000	1.750	BUSH97
1 1/4"	CGFP499	D	0.938	1.000	1.188	2.375	BUSH911
1 1/4"	CGFP4911	D	0.938	1.188	1.375	2.375	BUSH99
1 1/2"	CGFP599	D	0.938	1.000	1.188	2.375	BUSH911
1 1/2"	CGFP5911	D	0.938	1.188	1.375	2.375	BUSH99
2"	CGFP6913	E	1.000	1.375	1.625	3.250	BUSH913
2"	CGFP6915	E	1.000	1.625	1.875	3.250	BUSH915
2 1/2"	CGFP7917	F	1.438	1.875	2.188	3.250	BUSH917
2 1/2"	CGFP7920	F	1.438	2.188	2.500	3.250	BUSH920
3"	CGFP8917	F	1.500	1.875	2.188	3.250	BUSH917
3"	CGFP8920	F	1.500	2.188	2.500	3.250	BUSH920
3 1/2"	CGFP923	G	1.563	2.500	3.000	4.250	BUSH923
3 1/2"	CGFP927	G	1.563	3.000	3.500	4.250	BUSH927
4"	CGFP1023	G	1.625	2.500	3.000	4.250	BUSH923
4"	CGFP1027	G	1.625	3.000	3.500	4.250	BUSH927

All dimensions in inches.

