

KSH SERIES - Universal Industrial T5 or T8

reflect-a-light®

High Profile Strip Kit

✓ Made in USA ✓ Adjustable Bracket ✓ Universal Lamps ✓ High Ceilings

Applications

- Warehouses
- Aisles
- Retail

Benefits

- Instant On - Re-Strike
- Up To 90% Energy Savings
- EPACT and Utility Rebates

Features

- Toolless Ballast Acces
- BAA Qualified
- ETL Certified

Photometry


- 2 Lamp 4' T8 - KSH-02B04-SA
- Efficiency: 92.5%
- 0-DEG: 1.3
- 90-DEG: 1.2
- Report Number: 1654

Design

- Reflector Dimensions: 48.00" x 10.25" x 1.50"
- Reflectors produced on high speed roll form for consistent high quality
- Adjustable channel width bracket for 4" - 5" Kits
- One-piece adjustable center bracket for 1 or 2 lamps
- Quarter turn reflector design
- Sockets snap-in & twist-lock

Existing Fixture	Input Watts	System Lumens
4 Lamp F40 T12	192	9120
2 Lamp F40 T12	96	4560
4 Lamp F34 T12	144	7930
2 Lamp F34 T12	72	3960
Retrofit Options	Input Watts	System Lumens
2 Lamp F32 T8 Normal	57	5192
2 Lamp F32 T8 Low	51	4602
2 Lamp F32 T8 High	75	6961
2 Lamp F28 T8 HE/Normal	49	4654
2 Lamp F28 T8 HE/Low	43	4119
2 Lamp F28 T8 HE/High	66	6152

*Lamp/ballast information provided from GE based on Proline ballast and F32T8/SPX41/ECO lamps.
High efficient system based on GE Ultra Max ballast and F28T8/SPX41/ECO lamps

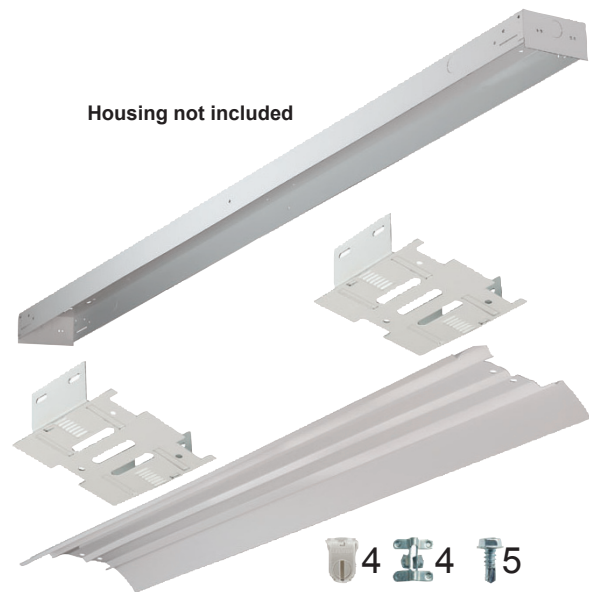

shown above: Reflector 1 Brackets 2

Kit Ordering Guide Example

KSH-UB04-SA-FLS

Series	Lamps	Wattage	Length	Material	Sockets
KSH	U - Universal	B - T8 C - T5	02 - 2' 03 - 3' 04 - 4' 06 - 6' 08 - 8'	EA - 95% Enhanced Aluminum SA - 86% Specular Aluminum WA - 91% White Aluminum	FLS - Shunted FLN - Non Shunted

Option Ordering Guide

See Standard Option Guide



Industry Leader in
Customization + Lead Times
for Over 25 Years

VIDALIA, GA
1-800-537-1629

US Energy Sciences
reflecting technology™