

Type
Project
Catalog No.
Lamp/Wattage

NHRIC-926QAT
6" IC Remodel Sloped Ceiling Housing
 Lamp: (1) 75PAR/R30 or (1) 40A19

PRODUCT DESCRIPTION

Six in ch thermally protected universal incandescent downlight for use in 2/12 - 6/12 pitch sloped ceilings. Rated for direct contact with insulation.

CONSTRUCTION

Maximum Angle

Pitch: 12/12; Angle: 45° (with designated trim)

HOUSING

.035 white finished housing. Riveted wrap and dome cap construction. Integral fold-out torsion spring brackets. Knockouts near top of housing provided for coil springs. Structural arm constructed of .045 galvanized steel connects housing to electrical junction box.

AIR FLOW RESTRICTION

Airtight (AT) unit restricts air flow to Plenum to ≤ 1.5 ft³ / minute to comply with Washington State Electric Code (WSEC).

ELECTRICAL

SOCKET

Standard medium base socket with protective cap included to protect electrical connection during ceiling painting. Heavy duty .095 curved steel bracket allows lamp position adjustment to compensate for ceiling pitch. Wing nuts lock desired angles

JUNCTION BOX

Plaster frame integrated 25 cu. in. junction box .060 galvanized steel with three 1/2", two 3/4", and four Romex connecting pryouts. Electrical connections are made through one side of the junction box wrap. Electrical grounding automatic when feeding with grounded steel EMT pipe or flex. Green wire provided for installations with ground wire fed through PVC pipe conduit.

LAMP

(1) 75PAR/R30
 (1) 40A19

THERMAL PROTECTOR

Standard UL thermal protector rated for 90 degrees Celsius is affixed to interior surface of fixture housing.

ACCESSORIES *sold separately*

NT-28	Eyeball Trim	White, Black
NT-29	Eyeball Trim	Copper, Gold
NTM-52	Open Gimbal Ring	White, Black, Copper, Gold
NTP-614	Deep Baffle	White, Black
NTS-615	Reflector	White, Black, Copper, Gold


LABELS AND LISTINGS

cULus Listed for damp locations, Junction box listed for maximum of 8 #12AWG conductors for feed-through.



DIMENSIONS

NHRIC-926QAT

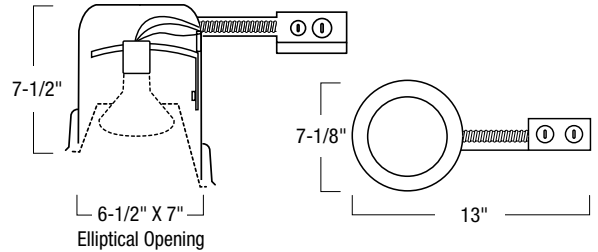

Opening : 6-1/2" x 7"
 Height : 7-1/2"
 Width : 7-1/8"
 Length: 13"

6" IC Remodel Sloped Ceiling Housing

Catalog No.
NHRIC-926QAT