


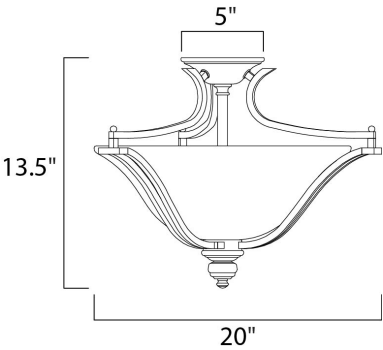

Measurements:

<u>Height</u>	<u>Width</u>		
13.50"	20.00"		
<u>Hanging Weight</u>	<u>Canopy Width</u>	<u>Canopy Height</u>	<u>Canopy Length</u>
6.60 lb	5.00"	1.50"	5.00"

Lamping:

Incandescent MB Incandescent	3,450 Rated Lumens
3.00 100W MB Incandescent	Color Temperature
300 total watt	2,500 Rated Life
Dimmable : Standard	

Shipping:

<u>Carton Weight</u>	<u>Carton Width</u>	<u>Carton Height</u>	<u>Carton Length</u>
9.46 lb	20.07"	9.84"	21.65"
<u>Master Pack Qty</u>	<u>UPC</u>	<u>UPS</u>	
1.0000	783209088443	Yes	

Finish:

Satin Silver SS

Glass:

Ice IC

Material:

Steel

Certification:

Dry Location

Additional:

MB Incandescent (Not Included)