

# RAB LIGHTING GT500RW



JOB NAME: \_\_\_\_\_

DATE: \_\_\_\_\_

TYPE: \_\_\_\_\_

## DESCRIPTION

Gotcha Sensor with two weatherproof, corrosionproof floodlights and universal CU4 cover plate. New vandal resistant lens Lamps not supplied.

## SPECIFICATIONS

### Detector Sensitivity:

Adjustable from 100% to 50%

### Floodlights:

Made of tough, corrosion-resistant polycarbonate. For extra or replacement floodlights, order cat# TUFFY in your choice of color. Accepts PAR-38 lamps, medium base, 150 watts max. Lamps not included.

### Photoelectric Control:

Deactivates lights during daylight

### Power Consumption:

1 watt

### Sensor Housing:

Made of tough, corrosion resistant polycarbonate

### Surge Protection:

Withstands up to 6000 volts

### Time Adjustment:

10 seconds to 5 minutes

### UL Listing:

Suitable for wet locations.

### Voltage:

120 volts AC 60 Hz.

### Wall Switch Manual Override:

Two flip logic prevents activation by momentary power outages. Override resets to auto after 6 hours or at dawn. No extra wiring needed.

### Detection:

110° view

### Patents:

RAB sensor and fixture designs are protected under U.S. and International Intellectual Property laws


### Color:

White


### Weight:

1.65

## DIMENSIONS

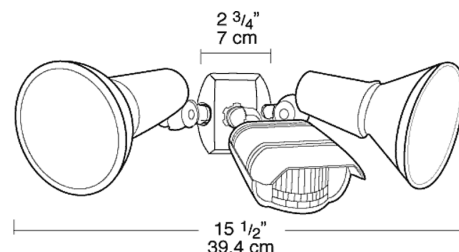

## DETECTION PATTERN

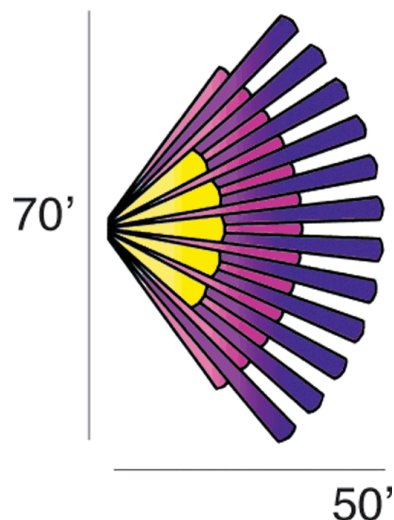

Note: Specifications may change without notice

**RAB Lighting, Inc.** • 170 Ludlow Ave • Northvale, NJ 07647 • Tel: 888 RAB-1000 • Fax: 888 RAB-1232 • [www.rabweb.com](http://www.rabweb.com)  
© 2008