



Image File Name: **F738-WHF.jpg**

Item #  
**F738-WHF**

Product Family Name:  
**Pancake**

Category:  
**INTERIOR FAN**

Certification  
**3064964**


Patents:  
U.S. Patent(s): D750,215; D750,219; 9,810,227 Add'l U.S. Patent(s)  
Pending

Notes:

UPC Code:  
**706411045493**

Finish:  
**Flat White**

Category Type:  
**Ceiling Fan**

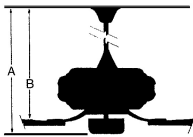

MEASUREMENTS

Blade Finish:		Reversible Blades:	
		<b>No</b>	
Blade Material:		Slope:	
<b>ABS Construction</b>		<b>Yes</b>	
Blade Sweep:	No. of Blades:	Blade Pitch:	Hanging Weight:
<b>52"</b>	<b>4</b>	<b>14</b>	<b>14.44</b>
Downrod 1:	Downrod 1 Outside	Downroad 2:	Downrod 2 Outside
<b>6</b>	Dia:		Dia:
	<b>0.75</b>		
Ceiling to Lowest	Ceiling to Blade	Lead Wire:	Motor Size:
Point: (Dim A)	(Dim B)	<b>12"</b>	<b>DC/153X18MM</b>
<b>9.75</b>	<b>7.75</b>		

	Low	Low/Med.	Medium	Med/High	High
<b>RPM:</b>	71				178
<b>Amps:</b>	0.238				0.52
<b>Watts:</b>	12.7				63.0
<b>CFM:</b>	872.0				3941.0
<b>CFM/Watts:</b>	68.66				62.56

LAMPING

No. of Bulbs:	Light Type:			
<b>0</b>				
Max Bulb	Socket:			
Wattage:				
Light Kit:	Dimmable:	Ballast:	Rated Life	Uplight:
<b>No</b>	<b>No</b>		Hours:	<b>No</b>
Bulb/LED	Color Temp.:	GRI:	Initial Lumens:	Delivered
Included:			Lumens:	Lumens:

GLASS

Description:	Material:
Part No.:	Quantity:
Width:	Height:
	Length:



SHIPPING

Carton Width:	Carton Height:	Carton Length:
<b>13.57</b>	<b>5.75</b>	<b>25.25</b>
Carton Weight:	Carton Cubic Feet:	Small Package Shippable:
<b>16.72</b>	<b>1.14</b>	<b>Yes</b>
Master Pack Width:	Master Pack Height:	Master Pack Length:
Master Pack Weight:	Master Cubic Feet:	Multi-Pack:
		<b>1</b>



ETL  
Intertek



**WARNING:** Handling this product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. Wash hands with soap and water after installing, handling, cleaning or otherwise touching this product. For more information go to: [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

For additional information, please contact Customer Care: 1-800-221-7977 | Product depicted on this spec sheet is protected by United States Federal and/or State laws including US Patent, Trademark and/or Copyright and unfair competition laws. Unauthorized reproduction or use carries severe legal penalties.