

Mark 10 Powerline

MARK 10 POWERLINE VEZ2Q26M2LDK

For companies looking to make their fixed-output linear T8, 4-pin CFL, and T5/HO fluorescent systems more cost effective and sustainable, Mark 10 Powerline ballasts provide an easy solution without the need for additional control leads. Simply, (1) replace the ballast, (2) replace the switch, (3) dim the lights, that is all it takes. It's that easy to bring the convenience and flexibility of fluorescent dimming to conference rooms, private offices, auditoriums, architectural cove lighting – anywhere dimming is required.

Product data


General Information			
Lamp Type	CFQ26W/G24Q	Input Power (Min)	16 W
Number Of Lamps	2 piece/unit	Rated Lamp Power	26 W
Ballast Type	Dimmable Fluorescent	Wiring	
Base Model	VEZ2Q26M2LD	Color Input Terminals	Black and White
Suitable For Outdoor Use	Yes	Color Output Terminals	RED, YEL & BLU
Automatic Restart	Yes	Wire Striplength	0.375 mm
Operating and Electrical		Control Wire Gauge	NA
Input Voltage	277 V	Lamp Connection	Series
Input Frequency	60 Hz	Wire Length By Color	No wires
Total Harmonic Distortion USA	10 %	Wire Gauge (Nom)	18AWG mm
Ignition Method	Programmed Start	Wire Type	Solid
Crestfactor (Nom)	1.6	Remote Wiring Configuration Allowed	No
Ignition Time (Nom)	1.5 s	Tandem Wiring Configuration Allowed	No
Ballast Factor (Max)	1	Through Wiring Configuration Allowed	No
Ballast Factor (Min)	0.05	Max Ballast-Lamp Distance Remote Wiring	No Remote
Power Factor (Nom)	0.98	Max Ballast-Lamp Distance Tandem Wiring	No Tandem
Input Current (Nom)	0.21 A	Max Ballast-Lamp Distance Through Wiring	No Through
Input Power (Max)	58 W	Connector Type	Poke-In

Mark 10 Powerline

Temperature	
T-Case Maximum (Nom)	70 °C
Mechanical and Housing	
Housing Material	Metal
Housing	M2
Housing Dimensions	4.98" x 3.0" x 1.29"
Approval and Application	
EMC Immunity Standard	FCC Consumer
Approval Marks	CSA certificate UL certificate CEC Listing RoHS Compliant
Hum And Noise Level	A

UL Recognized	No
Product Data	
Order product name	MARK 10 POWERLINE VEZ2Q26M2LDK
EAN/UPC - Product	781087028117
Order code	913710251104
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	913710251104
Net Weight (Piece)	432.000 g

Dimensional drawing

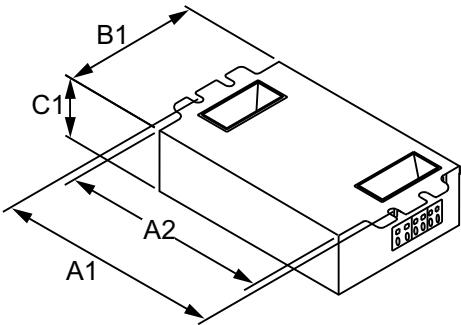

Product	A1	A2	B1	C1
MARK 10 POWERLINE VEZ2Q26M2LDK	4.55 in	4.20 in	3.00 in	1.29 in

ELE DIM BAL (2) 26W CFL (4-PIN) 277V KIT

