



PL-L Long 4-Pin Base

PL-L 40W/841/4P/RS/IS


Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.

Product data

General Information		Lamp Current (Nom)		Voltage (Nom)	
Cap-Base	2G11 [2G11]		0.320 A		126 V
Life To 50% Failures (Nom)	10000 h				
System Description	Rapid Start (RS)				
Light Technical		Controls and Dimming			
Color Code	841 [CCT of 4100K (841)]	Dimmable	Yes		
Initial lumen (Nom)	3500 lm	Mechanical and Housing			
Color Designation	Cool White (CW)	Cap-Base Information	4P		
Lumen Maintenance 10000 h (Nom)	91 %	Product Data			
Lumen Maintenance 2000 h (Nom)	94 %	Order product name	PL-L 40W/841/4P/RS/IS		
Lumen Maintenance 5000 h (Nom)	92 %	EAN/UPC - Product	046677111809		
Chromaticity Coordinate X (Nom)	380	Order code	300442		
Chromaticity Coordinate Y (Nom)	380	Numerator - Quantity Per Pack	1		
Correlated Color Temperature (Nom)	4100 K	Numerator - Packs per outer box	25		
Luminous Efficacy (rated) (Nom)	87 lm/W	Material Nr. (12NC)	927908008429		
Color Rendering Index (Nom)	82	Net Weight (Piece)	140.000 g		
		ILCOS Code	FSD-40/40/1B-L/P-2G11		
Operating and Electrical					
Power (Rated) (Nom)	36.3 W				

PL-L Long 4-Pin Base

Dimensional drawing

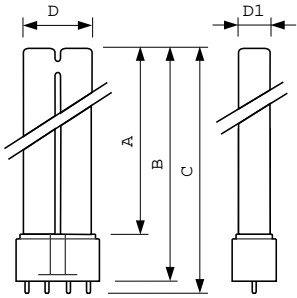

Product	D	D1	A	B	C
PL-L 40W/841/4P/RS/IS	39 mm	18 mm	540 mm	565 mm	571.6 mm

PL-L 40W/840/4P RS

