



Item #
F521-WHF

Product Family Name:
Aluma

Category:
INTERIOR FAN

Certification
E75795

Patents:

Notes:

UPC Code:
706411040030


Finish:
Flat White

Category Type:
Ceiling Fan



Cap for Non-Light Use (Incl.)

Image File Name: F521-WHF.jpg

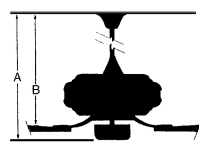

MEASUREMENTS

Blade Finish:

Blade Material:
Plywood Construction

Blade Sweep:
52"

Downrod 1:
6

Ceiling to Lowest Point: (Dim A)
15.75

No. of Blades:
4

Downrod 1 Outside Dia:
0.75

Ceiling to Blade (Dim B)
12.25

Blade Pitch:
11.5 DEGREES

Downroad 2:
16.93

Lead Wire:
80"

Reversible Blades:
No

Slope:
Yes

Hanging Weight:
16.93

Downrod 2 Outside Dia:

Motor Size:
153X15MM

	Low	Low/Med.	Medium	Med/High	High
RPM:	58				184
Amps:	0.184				0.535
Watts:	7.07				63.62
CFM:	1405.46				4237.32
CFM/Watts:	198.79				66.6

LAMPING

No. of Bulbs:
1

Max Bulb
Wattage:
100

Light Kit:
Yes

Light Type:
T-4,Mini-Can

Socket:
E11,MINI-CAN

Dimmable:
Yes

Ballast:

Rated Life
Hours:

Uplight:
No

Bulb/LED
Included:
Yes

Color Temp.:

GRI:

Initial Lumens:
Delivered Lumens:

GLASS

Description:
Etched Opal

Part No.:
GF521

Width:

Material:
GLASS

Quantity:
1

Length:



FAN CONTROLS

Pull Chain Control:
No

Works with Remote Control:
Yes

Included Remote Control:

Compatible Remote Control(s):
RCS213,RCS223

Works with Wall Control:
Yes

Included Wall Control:
WC106-WH

Compatible Wall Control(s):
WCS213,WCS223



SHIPPING

Carton Width:
11.88

Carton Weight:
19.43

Master Pack Width:

Carton Height:
10.25

Carton Cubic Feet:
1.691

Master Pack Height:

Carton Length:
24.0

Small Package Shippable:
Yes

Master Pack Length:

Master Pack Weight:

Master Cubic Feet:

Multi-Pack:
1

Master Pack:



Title 17



UL Listed

For additional information, please contact Customer Care: 1-800-221-7977 | Product depicted on this spec sheet is protected by United States Federal and/or State laws including US Patent, Trademark and/or Copyright and unfair competition laws. Unauthorized reproduction or use carries severe legal penalties.