



One Circuit Track Power System

IS4 / IS6 / IS8

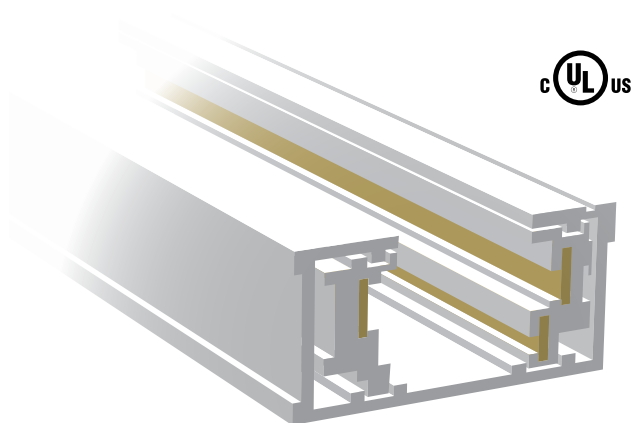

JOB NAME		CATALOG NUMBER	
NOTES		TYPE	

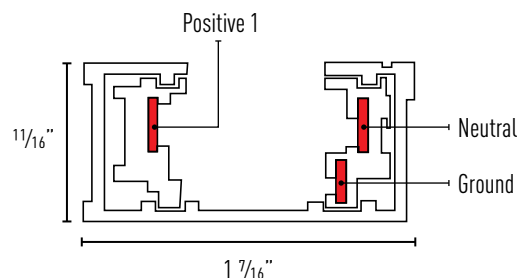

CATALOG #	DESCRIPTION	LENGTH (ft)	FINISH
IS4B	4' Single Circuit / Single Neutral Track	4'	Black
IS4SV	4' Single Circuit / Single Neutral Track	4'	Silver
IS4W	4' Single Circuit / Single Neutral Track	4'	White
IS6B	6' Single Circuit / Single Neutral Track	6'	Black
IS6SV	6' Single Circuit / Single Neutral Track	6'	Silver
IS6W	6' Single Circuit / Single Neutral Track	6'	White
IS8B	8' Single Circuit / Single Neutral Track	8'	Black
IS8SV	8' Single Circuit / Single Neutral Track	8'	Silver
IS8W	8' Single Circuit / Single Neutral Track	8'	White

DESCRIPTION

Single circuit / single neutral track is an affordable and durable solution that features easy installation. Track system is available in 4, 6, and 8-foot sizes. Track is supplied with (1) dead end cap and mounting hardware. Live end sold separately. Dimming feature available, see track luminaire for dimming compatibility. Track may be field cut to accommodate custom lengths.

CONSTRUCTION

Extruded aluminum construction
Extruded PVC insulated solid 12-gauge copper line conductor
Polarity groove is located on face of track to indicate location of grounding conductor.

ELECTRICAL

Voltage: 120V 60Hz / 20A Max. 2400 watts maximum

FINISHES

Powder coat white, black or silver

LISTING/WARRANTY

- UL Listed to US and Canadian Standards for Dry Locations.
- One (1) Year Limited Warranty

TRACK LUMINAIRE COMPATIBILITY

All Intense track fixtures are designed for use with single or two circuit track power systems. When using the track luminaire on a single circuit system, the positive line connector should be in the down position (positive 1). To move the connector to the forward position, push lever up with a flat head screwdriver or pliers. All Intense track heads are shipped in the standard single position.

Track Accessories

Single Circuit / Single Neutral Track Power System

JOB NAME		CATALOG NUMBER	
NOTES		TYPE	



Single Circuit Track Current Limiter End Feed

Limits the amount of electrical load that can be placed on the circuit. Self luminous ON/OFF breaker switch.

Specify Limiter Amperage:

-1A (120W/1A), -2A (300W/2.5A), -5A (600W/5A), -7A (900W/7.5A)
-10A (1200W/10A), -12A (1440W/12A)

IS125B	Single Circuit Current Limiter End Feed, Black
IS125SV	Single Circuit Current Limiter End Feed, Silver
IS125W	Single Circuit Current Limiter End Feed, White



Single Circuit Track Current Limiter In-Line Feed

Limits the amount of electrical load that can be placed on the circuit. Self luminous ON/OFF breaker switch.

Specify Limiter Amperage:

-1A (120W/1A), -2A (300W/2.5A), -5A (600W/5A), -7A (900W/7.5A)
-10A (1200W/10A), -12A (1440W/12A)

IS126B	Single Circuit Current Limiter In-Line, Black
IS126SV	Single Circuit Current Limiter In-Line, Silver
IS126W	Single Circuit Current Limiter In-Line, White



Single Circuit Track Current Limiter End Feed (Title 24 Compliant)

Limits the amount of electrical load that can be placed on the circuit. Self luminous ON/OFF breaker switch. Includes 12" permanently mounted track with end cap, must order track connector separately.

T24

Specify Limiter Amperage:

-1A-T24 (120W/1A), -2A-T24 (300W/2.5A), -5A-T24 (600W/5A),
-7A-T24 (900W/7.5A), -10A-T24 (1200W/10A), -12A-T24 (1440W/12A)

IS125B	Single Circuit Current Limiter End Feed, Black
IS125SV	Single Circuit Current Limiter End Feed, Silver
IS125W	Single Circuit Current Limiter End Feed, White



Single Circuit Track Current Limiter In-Line Feed (Title 24 Compliant)

Limits the amount of electrical load that can be placed on the circuit. Self luminous ON/OFF breaker switch. Includes 12" permanently mounted tracks with end caps, must order track connectors separately.

T24

Specify Limiter Amperage:

-1A-T24 (120W/1A), -2A-T24 (300W/2.5A), -5A-T24 (600W/5A),
-7A-T24 (900W/7.5A), -10A-T24 (1200W/10A), -12A-T24 (1440W/12A)

IS126B	Single Circuit Current Limiter In-Line, Black
IS126SV	Single Circuit Current Limiter In-Line, Silver
IS126W	Single Circuit Current Limiter In-Line, White



Single Circuit Track Current Limiter Mini End Feed

Limits the amount of electrical load that can be placed on the circuit. Self luminous ON/OFF breaker switch.

Specify Limiter Amperage:

-1A (120W/1A), -2A (300W/2.5A), -5A (600W/5A), -7A (900W/7.5A)
-10A (1200W/10A), -12A (1440W/12A)

IS135B	Single Circuit Current Limiter Mini End Feed, Black
IS135SV	Single Circuit Current Limiter Mini End Feed, Silver
IS135W	Single Circuit Current Limiter Mini End Feed, White



Single Circuit Track Current Limiter Mini End Feed (Title 24 Compliant)

Limits the amount of electrical load that can be placed on the circuit. Self luminous ON/OFF breaker switch. Includes 12" permanently mounted track with end cap, must order track connector separately.

T24

Specify Limiter Amperage:

-1A-T24 (120W/1A), -2A-T24 (300W/2.5A), -5A-T24 (600W/5A),
-7A-T24 (900W/7.5A), -10A-T24 (1200W/10A), -12A-T24 (1440W/12A)

IS135B	Single Circuit Current Limiter Mini End Feed, Black
IS135SV	Single Circuit Current Limiter Mini End Feed, Silver
IS135W	Single Circuit Current Limiter Mini End Feed, White



Single Circuit Live End

IS101B	Single Circuit Live End, Black
IS101SV	Single Circuit Live End, Silver
IS101W	Single Circuit Live End, White



Single Circuit T-Connector

Can be utilized as a power feed.

IS105B	Single Circuit T-Connector, Black
IS105SV	Single Circuit T-Connector, Silver
IS105W	Single Circuit T-Connector, White



Single Circuit Straight Feed Connector

Can be utilized as a power feed.

IS103B	Single Circuit Straight Feed, Black
IS103SV	Single Circuit Straight Feed, Silver
IS103W	Single Circuit Straight Feed, White



Single Circuit 90° Connector

Can be utilized as a power feed.

IS106B	Single Circuit 90° Connector, Black
IS106SV	Single Circuit 90° Connector, Silver
IS106W	Single Circuit 90° Connector, White



Single Circuit Flexible Connector

Cannot be utilized as a power feed.

IS104B	Single Circuit Flexible Connector, Black
IS104SV	Single Circuit Flexible Connector, Silver
IS104W	Single Circuit Flexible Connector, White



Single Circuit Conduit End Feed

IS109B	Single Circuit Conduit End Feed, Black
IS109SV	Single Circuit Conduit End Feed, Silver
IS109W	Single Circuit Conduit End Feed, White



Single Circuit X-Connector

Can be utilized as a power feed.

IS107B	Single Circuit X-Connector, Black
IS107SV	Single Circuit X-Connector, Silver
IS107W	Single Circuit X-Connector, White



Single Circuit Floating Canopy

IS110B	Single Circuit Floating Canopy, Black
IS110SV	Single Circuit Floating Canopy, Silver
IS110W	Single Circuit Floating Canopy, White



Single Circuit Mini Coupling

IS108B	Single Circuit Mini Connector, Black
IS108SV	Single Circuit Mini Connector, Silver
IS108W	Single Circuit Mini Connector, White



Single Circuit Live End With Box Cover

IS114B	Single Circuit Live End w/ Cover, Black
IS114SV	Single Circuit Live End w/ Cover, Silver
IS114W	Single Circuit Live End w/ Cover, White

TRACK SYSTEM L/M-0522-15 P-2

Intense Lighting, LLC | 3340 E La Palma Ave. | Anaheim, CA 92806 | Phone: 1.800.961.5321 | Fax: 1.800.961.5322 | www.intenselightning.com

Note: Specifications and dimensions subject to change without notice.



Track Accessories


Single Circuit / Single Neutral Track Power System

JOB NAME		CATALOG NUMBER	
NOTES		TYPE	



Single Circuit Conduit Continuation Kit

IS119B	Single Circuit Conduit Continuation Kit, Black
IS119SV	Single Circuit Conduit Continuation Kit, Silver
IS119W	Single Circuit Conduit Continuation Kit, White

 

Monopoint Canopy

Mounts permanently to outlet box.

IS117B	Monopoint Canopy, Black
IS117SV	Monopoint Canopy, Silver
IS117W	Monopoint Canopy, White



Single Circuit Track End Cap


IS115B	Single Circuit End Cap, Black
IS115SV	Single Circuit End Cap, Silver
IS115W	Single Circuit End Cap, White



C-Clamp Adapter

Can be mounted on a pipe up to 2" in diameter or any flat protruding surface. Includes 6' 3-wire cord with 3-prong grounded plug. Allows any fixture to be plugged directly into outlet.

IS58B	C-Clamp Adapter, Black
IS58W	C-Clamp Adapter, White

 

Track Outlet Box Cover

Covers J-Box and connects live end.

IS100B	Outlet Box Cover, Black
IS100SV	Outlet Box Cover, Silver
IS100W	Outlet Box Cover, White



Offset Monopoint Canopy For Select Low Voltage Fixtures

Off-set for low-voltage transformer. For use with ITV4, ITV8, ITV50, ITV20 and ITV23

IS118B	Monopoint Canopy, Black
IS118SV	Monopoint Canopy, Silver
IS118W	Monopoint Canopy, White



T-bar Attachment Clips For T-bar Drop Ceiling

Use (2) clips for 2' and 4' track, (3) clips for 6' and 8' track, (4) clips for 12' track

IS120	Single T-bar Clip
-------	-------------------



Pendant Adapter

Accepts cable pendants.

IS17B	Pendant Adapter, Black
IS17W	Pendant Adapter, White



Outlet Adapter

Provides electrical rece

IS113B	Outlet Adapter, Black
IS113W	Outlet Adapter, White

Track Suspension Kit

Track Suspension Kit

Each Intense Lighting track suspension kit includes a mounting canopy and stem that allow you to lower the entire track system from the ceiling. A wire cover and live end is required to power feed the track. The suspension kits are available in 12, 18, 24, 36 and 48-inch lengths, and in black, silver or white finishes. Stem diameter 1/2" and thread is 1/4-18 N.P.S.M.

ISP12B	12" Track Suspension Kit, Black
ISP12SV	12" Track Suspension Kit, Silver
ISP12W	12" Track Suspension Kit, White

ISP18B	18" Track Suspension Kit, Black
ISP18SV	18" Track Suspension Kit, Silver
ISP18W	18" Track Suspension Kit, White

ISP24B	24" Track Suspension Kit, Black
ISP24SV	24" Track Suspension Kit, Silver
ISP24W	24" Track Suspension Kit, White

ISP36B	36" Track Suspension Kit, Black
ISP36SV	36" Track Suspension Kit, Silver
ISP36W	36" Track Suspension Kit, White

ISP48B	48" Track Suspension Kit, Black
ISP48SV	48" Track Suspension Kit, Silver
ISP48W	48" Track Suspension Kit, White



Wire Cover

IS116B	Wire Cover, Black
IS116SV	Wire Cover, Silver
IS116W	Wire Cover, White



Single Circuit Live End

IS101B	Single Circuit Live End, Black
IS101SV	Single Circuit Live End, Silver
IS101W	Single Circuit Live End, White





* For aircraft cable suspension. See professional track power system

Track Head Accessories

Single Circuit / Single Neutral Track Power System

JOB NAME		CATALOG NUMBER	
NOTES		TYPE	

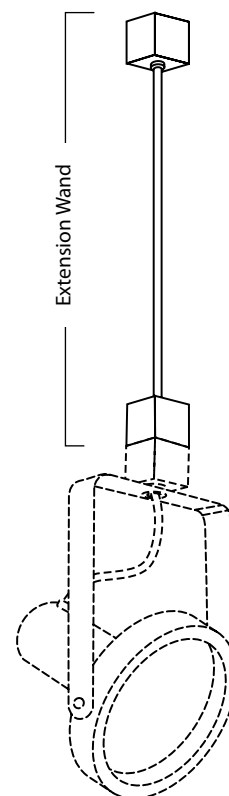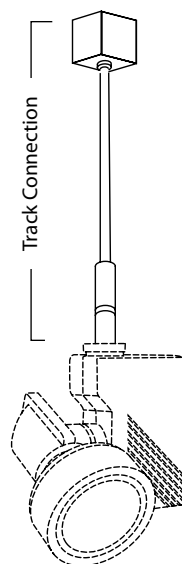

Track Connections

Track connections give the flexibility to put lighting where it is needed. Connections are available with line voltage and select low voltage track heads. Conveniently factory installed, track connections are a labor-free alternative. Specify track connection option after track fixture catalog number. Consult factory for track head capability. (Example: ITV4W-C18W)

CATALOG #	DESCRIPTION	FINISH
C12B	12" Connection Option	Black
C12SV	12" Connection Option	Silver
C12W	12" Connection Option	White
C18B	18" Connection Option	Black
C18SV	18" Connection Option	Silver
C18W	18" Connection Option	White

Extension Wand

Intense's extension wands extend track heads from the track system and are available in 12, 18, 24, 36 and 48-inch extensions for added flexibility. Extension wands can be used with line voltage, select LED, and select low voltage fixtures. They are also available in white and black finishes. Consult factory for track head compatibility.

CATALOG #	DESCRIPTION	FINISH
ISX12B	12" Extension Wand	Black
ISX12W	12" Extension Wand	White
ISX18B	18" Extension Wand	Black
ISX18W	18" Extension Wand	White
ISX24B	24" Extension Wand	Black
ISX24W	24" Extension Wand	White
ISX36B	36" Extension Wand	Black
ISX36W	36" Extension Wand	White
ISX48B	48" Extension Wand	Black
ISX48W	48" Extension Wand	White