

Type _____

Project _____

Catalog No. _____

Lamp/Wattage _____

NULS Ultra Slim T5 Fixtures

Low Profile T5 Fluorescent Under Cabinet Series

Lamp: Various T5 (Included with Fixtures)

PRODUCT DESCRIPTION

T5 Fluorescent slim, low profile under cabinet lighting fixtures ranging in length from 13-1/2" to 47" and 8 to 28 watts. Ideal for narrow spaces where bright even illumination is required.

LAMPS

NULS-8	8W F8T5/CW 4100K
NULS-13	13W F13T5/CW 4100K
NULS-18	18W F18T5/CW 4100K
NULS-21	21W F21T5/CW 4100K
NULS-24	24W F24T5/CW 4100K
NULS-28	28W F28T5/CW 4100K

FEATURES

- Ultra slim (7/8" width profile)
- Cool, white T5 lamp included
- Solid state electronic ballast
- Six sizes ranging 13-1/2" - 47"
- Daily-chain up to 10 fixtures together
- Straight connection for long, shadow-free runs
- Power cord and straight connector included
- Flexible connectors in 6", 12", 18", and 72" lengths
- Each fixture includes On/Off switch
- Simple, instant plug-in electrical connection
- Installation packet includes clips for invisible or "U" bracket mounting
- Flicker-free start up
- High performance, cool operation
- Instant and easy installation
- cULus Listed

HOUSING

.09 Injection Molded White Plastic Construction.

MOUNTING

Hardware provided for mounting fixture either to standard horizontal surface or vertical wall surface.

ELECTRICAL

Sockets accept bi-pin T5 fluorescent light source. Fixture contains recessed male connector for attachment to female receptacle from either 120V power cord or connector from other fixture. t to female receptacle from either 120V power cord or connector from other fixture. Rocker switch on side of fixture allows independent on/off control.

Note: 10 fixtures maximum may be connected together on single 120V power cord feed. Do not exceed 10 fixtures per feed.

INCLUDED WITH EVERY FIXTURE


6' cord and plug, straight connector, (2) "U" Clips, (2) perpendicular clips, (2) invisible clips, screws, On/Off switch, and Cool White T5 lamp.

LABELS AND LISTINGS

cULus Listed for Dry Location
cULus Listed as Portable Fixture



DIMENSIONS

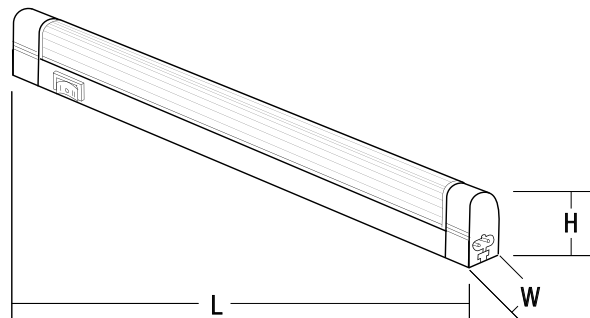

NULS-8	Width: 7/8" Length: 13-1/2" Height: 1-11/16"
NULS-13	Width: 7/8" Length: 22-1/2" Height: 1-11/16"
NULS-18	Width: 7/8" Length: 25-1/8" Height: 1-11/16"
NULS-21	Width: 0.898" Length: 35.327" Height: 1.673"
NULS-24	Width: 0.898" Length: 37.327" Height: 1.673"
NULS-28	Width: 7/8" Length: 47" Height: 1-11/16"

Low Profile T5 Fluorescent Under Cabinet Fixture

Catalog No.	Wattage / Length
NULS-8	8 = 13-1/2" F8T5/CW 4100K
	13 = 22-1/2" F13T5/CW 4100K
	18 = 25-1/8" F18T5/CW 4100K
	21 = 35-1/2" F21T5/CW 4100K
	24 = 37-1/4" F24T5/CW 4100K
	28 = 47" F28T5/CW 4100K

Accessories

NRA-125	Straight Connector (Included with Fixture)
NRA-125/6	6" Flexible Connector
NRA-125/12	12" Flexible Connector
NRA-125/18	18" Flexible Connector
NRA-125/72	72" Flexible Connector
NRA-143W	Right Angle Connector, White
NRA-6047	Mounting Clips, White
NUSP-JBox	J-Box for hard wiring, UL Listed includes male to male and male to female connector

Create a complete Catalog Item number: Example: NULS-8