



# DuraMax Three Way

30/100A/WL 120V 12/1

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs


## Product data

General Information	
Cap-Base	E26D [ 3 Contact Medium Screw]
Operating Position	S90 [ Standing +/-90D or Base Down (BDH)]
Main Application	General Lighting (G)
Gas Filling	Gas
Light Technical	
Luminous Flux (Max)	1260 lm
Luminous Flux (Min)	300 lm
Luminous Flux (Nom)	960 lm
Operating and Electrical	
Power (Rated) (Nom)	30-100 W
Voltage (Nom)	120 V

Mechanical and Housing	
Bulb Finish	Soft White
Cap-Base Information	Brass Cap
Filament Shape	2CC-8 [ Axial]
Product Data	
Order product name	30/100A/WL 120V 12/1
EAN/UPC - Product	046677169473
Order code	925176336309
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	925176336309
Net Weight (Piece)	0.036 kg

DuraMax Three Way

Dimensional drawing

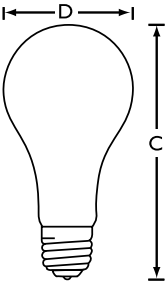

A21

30-70-100W E26d 120V A21 SW

Product	D	C (max)
30/100A/WL 120V 12/1	2.625 in	5.313 in

