



# Halogen A19

## Halogen 72A19/EV/NTL 120V 12/2

Halogen bulbs reduce energy consumption without sacrificing the qualities of a traditional bulb. They uniquely produce light more efficiently. They work with dimmer switches and are available in the familiar A-shape design. Use them in existing fixtures just as you would standard incandescents and your home will look great while you save energy.


### Product data

General Information	
Cap-Base	E26 [ Single Contact Medium Screw]
Operating Position	Universal [ Universal]
Main Application	General Lighting (G)
Gas Filling	GAS
Light Technical	
Initial lumen (Nom)	1200 lm
Color Rendering Index (Nom)	100
Operating and Electrical	
Power (Rated) (Nom)	72 W
Voltage (Nom)	120 V
Mechanical and Housing	
Bulb Finish	Daylight-Blue

Cap-Base Information	Aluminium [ Aluminium Cap]
Bulb Material	Soft Glass
Filament Shape	CC-8 [ Axial]
Product Data	
Order product name	Halogen 72A19/EV/NTL 120V 12/2
EAN/UPC - Product	50046677226997
Order code	226993
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	925620820601
Net Weight (Piece)	0.001 kg

## Halogen A19

### Dimensional drawing

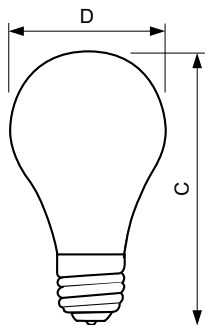

72W E26/ALC 120V A-19 D-B

#### Product

Halogen 72A19/EV/NTL 120V 12/2

