

Pro 205 - C205OB

52" Ceiling Fan with Light (Blades Sold Separately)

Finish: Oiled Bronze



Offering a vast array of finishes and blades, the Pro Builder Series makes it easy for you to bring Craftmade quality to your home or office. Pro Builder ceiling fans deliver an ideal combination of excellent performance and exceptional value.


- Standard, 3-Speed Reversible Motor
- 4" Downrod (Included)
- Blades Sold Separately
- White Frost Light Kit (3-60W Candelabra Bulbs Included)
- Dual Mount (Flat or Angled Ceiling)

Specs

Blade Sweep Opt (in.)	42, 52
Blades	5
Blade Pitch (deg)	12
Motor Size (MM)	153x13
Amps at High Speed	0.52
Watts (Hi Speed)	62.70
Energy Guide Watts	39
Energy Guide CFM	4635
Energy Guide CFM_Watts	74
High Speed (CFM)	4635.10
Low Speed (CFM)	1652.43
Shipping Weight (lbs.)	15.65
Carton Size (CU FT)	1.87
Blade Options	Type5
Bulb Wattage	60
Compatible Control Types	UCI-2000-2 Remote and Wall Control
Light Kit Options	Light Kit Included

Dimensions

A:	18.58
B:	10.72
C:	11.65
D:	5.12
E:	4.13
F: w/o Light Kit - Downrod Length (in.)	4

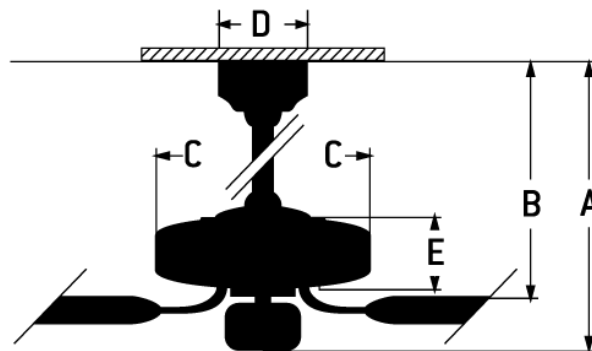

Downloads

Pro 205 - C205OB



[PDF Tear Sheet](#)



[Installation Guide](#)



[Energy Guide](#)

E205_Pro Builder_CFM.pdf 1 2/19/15 11:56 AM

ENERGY INFORMATION at High Speed		
Airflow	Electricity Use	Airflow Efficiency
4,635	63	74
Cubic Feet Per Minute	Watts (excludes lights)	Cubic Feet Per Minute Per Watt
Compare: 49" to 60" ceiling fans have airflow efficiencies ranging from approximately 51 to 176 cubic feet per minute per watt at high speed.		
Money-Saving Tip: Turn off fan when leaving room		