



Halogen A19

Halogen 29A19/EV/CL 120V 12/2

Halogen bulbs reduce energy consumption without sacrificing the qualities of a traditional bulb. They uniquely produce light more efficiently. They work with dimmer switches and are available in the familiar A-shape design. Use them in existing fixtures just as you would standard incandescents and your home will look great while you save energy.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Bulb Shape	A-19 (A19)
Operating Position	UNIVERSAL [Any or Universal (U)]
Main Application	General Lighting (G)
Gas Filling	Gas
Light Technical	
Luminous Flux Lamp @ 120V	380 lm
Operating and Electrical	
Power (Rated) (Nom)	29 W
Lamp Wattage Rated@120V	29 W
Voltage (Nom)	120 V
Mechanical and Housing	
Bulb Finish	Clear

Cap-Base Information	Aluminium Cap
Bulb Material	Glass
Filament Shape	CC-8 [Axial]
Product Data	
Order product name	Halogen 29A19/EV/CL 120V 12/2
EAN/UPC - Product	50046677410501
Order code	925702136301
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	925702136301
Net Weight (Piece)	0.005 kg

Halogen A19

Dimensional drawing

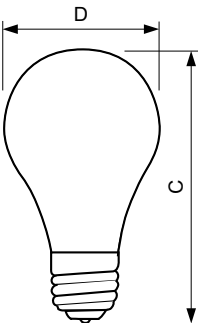

29W E26/ALC 120V A-19 Clear

Product	D	C
Halogen 29A19/EV/CL 120V 12/2	2.375 in	4.13 in

