

Rigid Straps

Snap-On Type - One Hole - Steel

Features

- Snap-on type Rigid strap with one holes
- Greater load bearing capability
- Easy to install

Applications

- Indoor or outdoor use
- Use to secure EMT, Rigid or IMC conduit to wood, masonry or where greater load bearing is required

Standard Material


- Steel

Standard Finish

- Zinc plated

Applicable Third Party Standards

- UL Standard: UL 2239
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB 1-2014

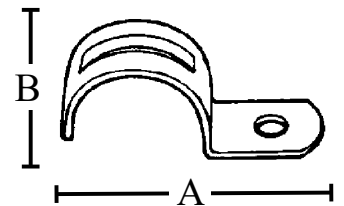

Catalog Number	UPC	Size	Unit Carton	Ship Case	Weight/Case	Inches	
						A	B
531A	15041	1/4"	100	1000	14	1.51	.562
531B	15045	3/8"	100	1000	12	1.81	.562
531	15050	1/2"	50	500	17	1.91	.625
532	15060	3/4"	50	500	25	2.21	.75
533	15070	1"	25	250	18	2.57	.875
534	15080	1-1/4"	20	200	18	2.79	.88
535	15090	1-1/2"	20	200	31	3.69	.899
536	15100	2"	10	100	24	4.17	1.14
517*	15670	2-1/2"	---	50	21	5	1.28
518*	15680	3"	---	25	12	5.55	1.28
519*	15690	3-1/2"	---	25	17	6.37	1.28
520*	15700	4"	---	25	17	6.87	1.28
520A	15702	5"	---	10	17	9	1.50
520B	15704	6"	---	10	20	10.35	1.50

*EMT and Rigid