




**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

GB26  
7818102312100  
4-2/0 CU-BAR 1 PC GRD  
Active

**Web Use**  
BURNDY Product Line

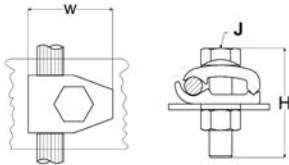

**Dimensional**

Width (in) 1.42  
Height (in) 1.74  
Size (Hex) or Size (Bolt) 3/8  
Thickness 0.25  
Size (Hex) or Size (Bolt) - in 0.38  
Width (Fraction) 1-3/7

**General**

Product Description

Mechanical Grounding Connector,  
Cable to 1/4" Thick Bar, 4 AWG  
(Sol)-2/0 AWG (Str), 3/8" Stud, 1-  
1/2 IN Width

**Conductor(s)**

Bar Thickness (Range) N/A  
Copper Solid Size (Range) 4 AWG-2/0 AWG  
Copper Stranded (Range) 4 AWG-2/0 AWG

**Physical**

Installation Torque 240  
Type of Plating Unplated  
Plated (Yes or No) N  
Product Material Copper Alloy

**Approvals / Certifications**

Rated for Direct Burial Y  
UL Listed Y  
CSA Certified Y  
ROHS Compatible Exempt  
UL Recognized N  
CULUS N  
Industry Standards UL467

**Documentation**

**For further technical assistance, please contact us**

**BURNDY LLC - USA**

47 East Industrial Park Drive  
Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
Monday - Friday  
Phone: 800-346-4175