



Mid sized wallpack. All aluminum precision die cast construction with tempered glass refractor. Lamp supplied.

Color: Bronze

Weight: 14.5 lbs

Project:

Type:

Prepared By:

Date:

Lamp Info

Type: ED17
Watts: 150W
Shape/Size: N/A
Base: N/A
ANSI: N/A
Hours: 24,000
Lamp Lumens: 16,000
Efficacy: 94 LPW

Ballast Info

Type: R-NPF 120V
120V: 4.5/3.2A
208V: N/A
240V: N/A
277V: N/A
Input Watts: 170W
Efficiency: 88%

Technical Specifications

Listings

UL Listing:

Suitable for wet locations. HID fixtures can be wired with 90_ C supply wiring if supply wires are routed 3" away from ballast.

Construction

Housing:

Die cast aluminum, 1/2" NPS tapped holes top, both sides and back for conduit or photocontrol. Hinged refractor frame. Continuous silicone rubber gasket.

Reflector:

Specular anodized aluminum, removable for installation. Symmetrical light pattern maximizes distance between fixtures.

Cutoff Lens:

Tempered glass.

Finish:


Formulated for high-durability and long lasting color.

Optical

Refractor:

Prismatic optics designed to minimize glare and throw light down and out. Heat resistant borosilicate glass.

Dimensions

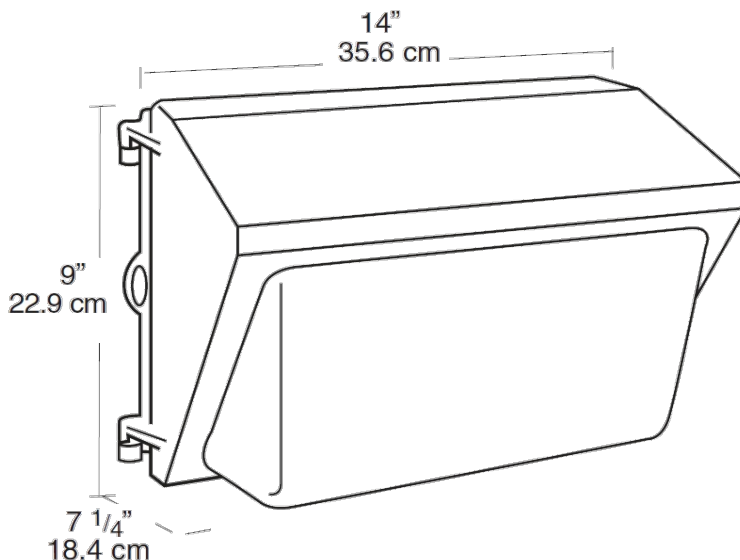

Features

- Precision die cast aluminum housing with durable polyester powder coating
- Tempered Glass Refractor
- Drilling template for easy box mounting
- Silicone gasket remains in place during relamping
- Top, side and back conduit openings
- Long life lamp included