

Rigid Conduit Bodies

Threaded C Type - Malleable Iron

Features

- NPT tapered hubs
- Suitable for use in concrete

Applications


- Provides access to conductors for maintenance and future system changes
- Connects conduit section

Standard Material

- Malleable iron

Standard Finish

- Zinc plated, aluminum enameled

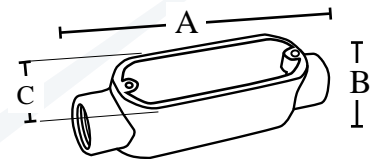

Catalog Number	UPC	Size	Wire Size		Internal Volume (in ³)	Ship Case	Weight/Case	Inches		
			Max. Number	Max. Size				A	B	C
C1M	20000	1/2"	---	---	4.5	10	7	5.35	1.31	1.31
C2M	20010	3/4"	3	6 AWG	7.5	10	23	6.00	1.62	1.48
C3M	20020	1"	3	4 AWG	12.5	5	6	7.06	1.88	1.75
C4M	20030	1-1/4"	3	2 AWG	32.3	5	23	9.25	2.50	2.40
C5M	20040	1-1/2"	3	1/0 AWG	35.3	2	26	9.25	2.67	2.40
C6M	20050	2"	3	3/0 AWG	73	1	26	11.50	3.29	3.05
C7M	20051	2-1/2"	3	250 MCM	138	1	10	15.00	3.9063	4.312
C8M	20052	3"	3	250 MCM	170	1	12	15.125	4.75	4.312
C9M	20053	3-1/2"	3	350 MCM	300	1	21	18.125	5.1875	4.875
C10M	20054	4"	3	350 MCM	328	1	23	18.125	5.5625	4.875