

FLOOD - model: WP-LED3

Endurance Wallpack

WAC LIGHTING


Responsible Lighting®

Fixture Type:

Catalog Number:

Project:

Location:

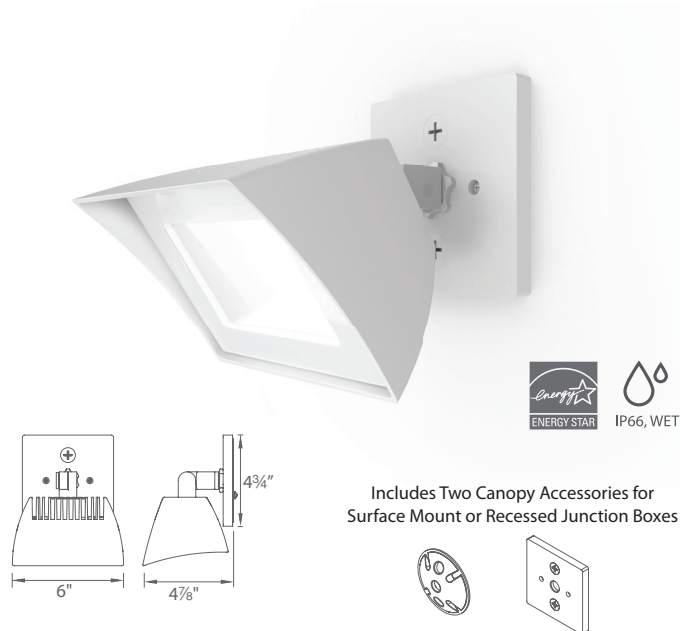

PRODUCT DESCRIPTION

Die cast aluminum factory sealed housings with patent pending design for a water and dust proof IP66 rated outdoor luminaire

FEATURES

- Factory-Sealed LED Light Engine
- 360° Horizontal Rotation, 90° Vertical Aiming
- Photo/Motion Sensor Compatible (Sold Separately)
- Suitable to install in all directions
- 120V Direct Wire - No Driver Needed
- Smooth and Continuous ELV Dimming
- 85 CRI
- 50,000 hour rated life

SPECIFICATIONS

Construction: Die-cast aluminum

Power: Line Voltage input (120V)


Dimming: 100% - 10% with Electronic Low Voltage (ELV) dimmer

Finish: Architectural Bronze, White and Graphite


Standards: Energy Star®, IP66, Wet Location, ETL & cETL Listed

Operating Temperature: -40°C (-40°F) to 40°C (104°F)

PHOTOMETRY

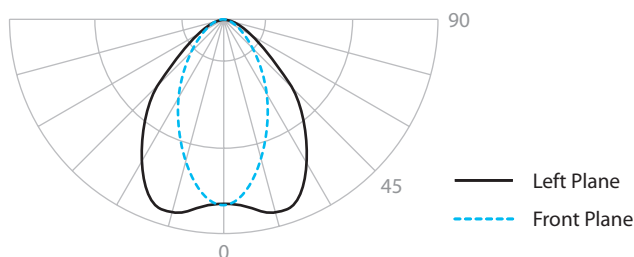



ORDER NUMBER

	Power	Comparable	Color Temp	Delivered Lumens	CBCP	Finish
	WP-LED335	35.5W	100W HID	30 3000K 2450 50 5000K 2730	1477 1642	aBZ Architectural Bronze aGH Architectural Graphite aWT Architectural White

- -

Example: **WP-LED336-30-BZ**

  ACCESSORIES



WAC Lighting

www.waclighting.com

Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center

44 Harbor Park Drive • Port Washington, NY 11050

Phone (516) 515.5000 • Fax (516) 515.5050

Western Distribution Center

1750 Archibald Avenue • Ontario, CA 91760

Phone (800) 526.2588 • Fax (800) 526.2585