




PRODUCT DESCRIPTION

Contemporary collection with sweeping arms and clean lines. Offered in Ice glass and Satin Nickel finish or Wilshire glass and Oil Rubbed Bronze finish.

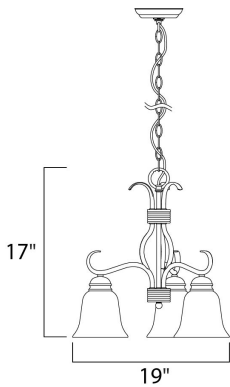

MEASUREMENTS

DIMENSION : 19." L x 19." W x 18.25" H
HANGING WEIGHT : 7.48 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 3,450 Rated
BULB : 3 x 60W (NOT INCLUDED), 180W Total
DIMMABLE : Dimmable

FINISHES OPTION

Oil Rubbed Bronze Ol



GLASS

Wilshire WS

MATERIAL

Steel

RATINGS

Dry Location
Dimmable



ADDITIONAL

ADJUSTABLE
INSTALL UP/DOWN:
RATED LIFE 2500 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com