


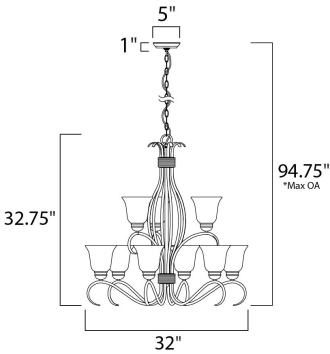

*max overall height

Measurements:

<u>Height</u>	<u>Width</u>
32.75"	32.00"
<u>Max OAH</u>	
94.75"	
<u>Hanging Weight</u>	
19.40 lb	

Lamping:

Incandescent MB	10,350 Rated Lumens
9.00 60W MB	Color Temperature
540 total watt	2,500 Rated Life
Dimmable : Standard	

Shipping:

<u>Carton Weight</u>	<u>Carton Width</u>	<u>Carton Height</u>	<u>Carton Length</u>
22.76 lb	9.25"	30.71"	34.06"
<u>Master Pack Qty</u>	<u>UPC</u>	<u>UPS</u>	
1.0000	783209025943	Yes	

Finish:	Satin Nickel SN
Glass:	Ice IC
Material:	Steel
Certification:	Dry Location Location
Additional:	MB (Not Included)