


H
SERIES
VERSATILE
UTILITY
LUMINAIRE

Job Name	
Catalog Number	
Notes	Type

Available with LED Express

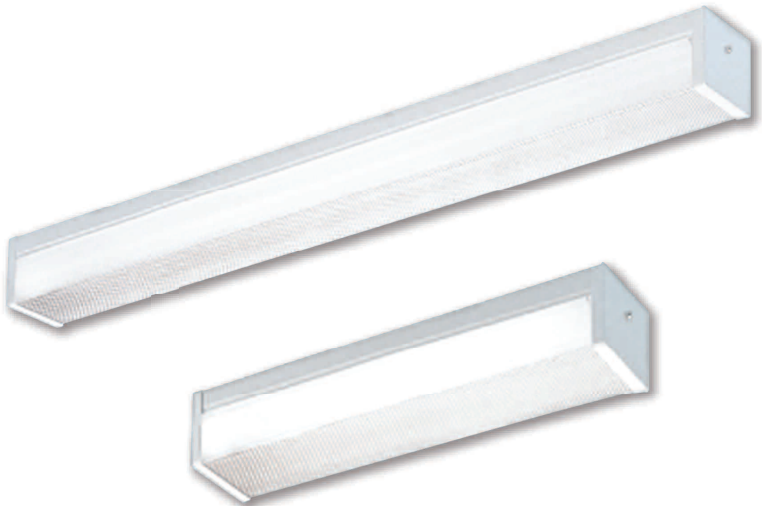

application

- Decorative all-purpose lensed luminaire, suitable for wall or ceiling mounting in residential, institutional or commercial applications
- Widely used in stairwells and corridors wired with factory installed emergency battery backup
- Able to be surface or pendant mounted individually or in continuous rows
- Available in 1 or 2 light, multiple lengths and numerous lamp/ballast combinations

diffuser

- One piece extruded clear, non-yellowing acrylic prismatic lens
- Features a prismatic pattern on the bottom and linear refractive sides for brightness control and 180° uniform light
- Grooved formation on the edges allows for a tight, no light leak attachment to the body
- Joiner band available for continuous runs, creating a finished appearance, supplied with tandem unit

construction

- The H series is an high quality fluorescent luminaire specifically designed for durable, hi-visibility areas
- Features durable steel bodies, quality paint finishes and superior electrical components
- Die formed from cold rolled steel for strength and uniformity
- Ends are die-formed for added strength
- The ends retain the diffuser with positive engagement reducing vibration hazards
- Wireway covers are die-formed for durability and attach easily and securely with two screws
- Ample knockouts are provided on back for convenient installation
- All fixtures are U.L. listed and IBEW union made

LaMar Lighting assumes no responsibility for misapplication of fixtures

electrical

- All electrical components are U.L. listed
- Electronic Class P ballasts standard

finish

- Prior to painting, all metal parts are treated with a multi-stage phosphate bonding process to ensure adhesion and inhibit rusting
- Painted with a lighting grade baked white enamel, having a reflectance factor exceeding 87% for premium quality and durability

LED EXPRESS

- Factory installation of LED tubes (internal or external driver)
- Internal driver: powered directly from the main AC voltage supplied to the fixture
- External driver: operates with a remote LED driver located within the luminaire that powers the linear tube with low voltage. There is no line voltage at the lamp-holders or within the tube.
- Ballast driven LED tube: designed with an internal circuitry that allows the tube to operate directly from the existing linear fluorescent ballast
- UL approved




H SERIES

VERSATILE FLUORESCENT
LUMINAIRE


ordering guide

Note: Tandem units contain double the amount of lamps shown

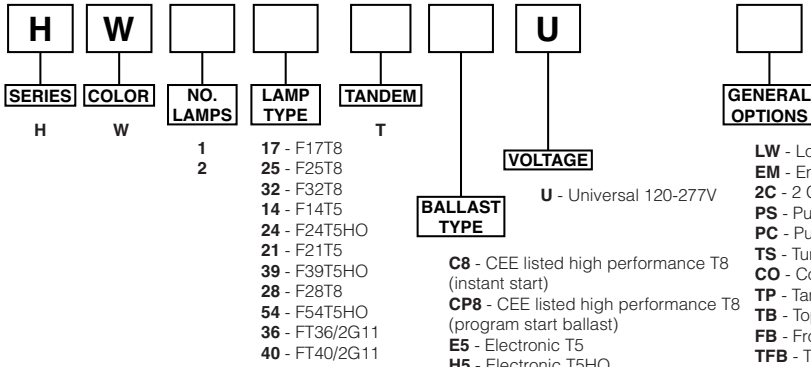

- LW - Low watt ballast (T8 only)
- EM - Emergency pack, 1 lamp 90 min. up to 500 lu.
- 2C - 2 Circuit (2L only)
- PS - Pull switch (120V)
- PC - Pull chain (120V)
- TS - Turn switch (120V)
- CO - Convenience outlet (120V)
- TP - Tamper-proof screws
- TB - Top baffle
- FB - Front baffle
- TFB - Top and front baffle
- CD - Center divider

LED ordering guide

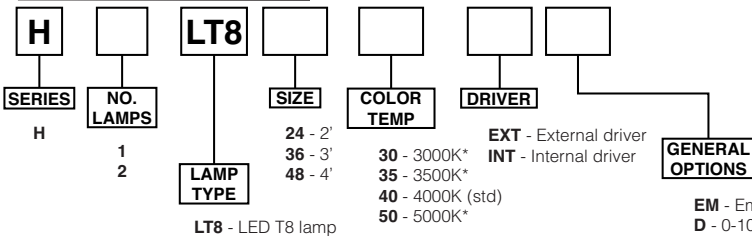

- EM - Emergency pack, 1 lamp 90 min. up to 500 lu. (consult factory)
- D - 0-10V dimming (consult factory)


*Not all lamp types available in all color temperatures (consult factory)

dimensional data


NOTE: SPECIFICATIONS AND DIMENSIONAL DATA ARE SUBJECT TO CHANGE WITHOUT NOTICE

accessories

switch and convenience outlets

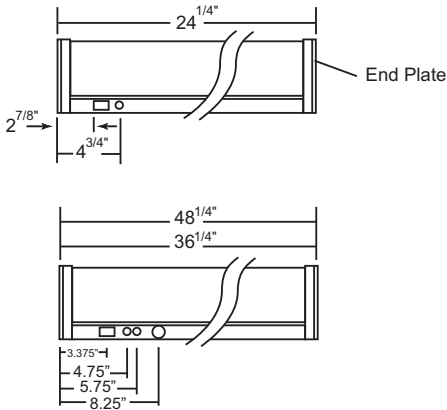

baffle options

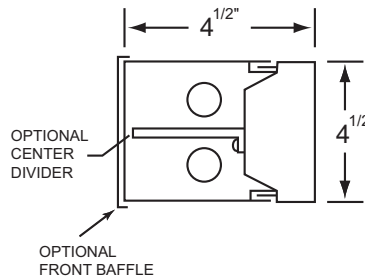

Ideal for hospital over bed patient application

- RFH Aluminum reflector
- Canopy Standard white 5" dia., 1/2" deep with hardware
- Stem Stem + Length needed

LAMP OPTIONS



- 13 T8/T5 841K
- 16 T8/T5 835K
- 11 T8/T5 830K

NOTE: In order to achieve rated lamp life, fixtures controlled by motion sensors should be ordered with programmed start ballasts when available and minimum time delay should be set to 15 minutes - Consult Factory

Multiple cord options are available - consult factory

Consult factory for additional options not shown or listed

back knockout plans and lengths

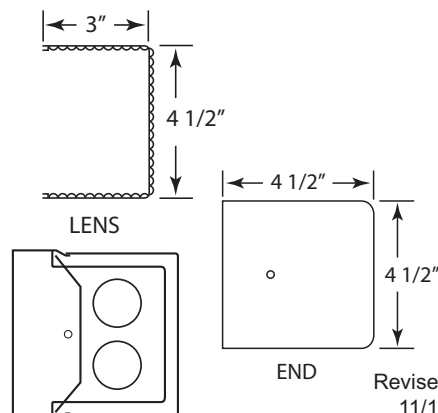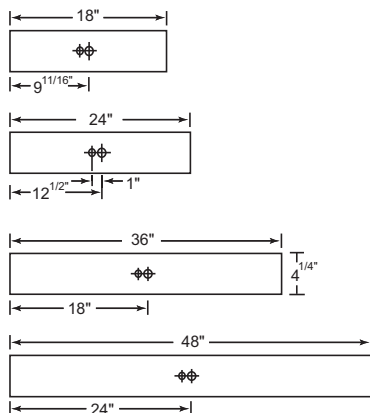

LaMar Lighting assumes no responsibility for misapplication of fixtures

Scan QR code to be directed to our home page!



**LaMar
Lighting**
Company, Inc.

LAMAR LIGHTING 485 Smith Street, Farmingdale, NY 11735 • Tel (631) 777-7700
Fax (631) 777-7705 • Outside NY (800) 724-7743 • www.lamarlighting.com

Revised
11/14