

Single Pole Devices and Temporary Power

150A, 600V AC/250V DC

Male Plugs



- Features
- Insulgrip® Style Housing for Superior Gripping
 - Non-Conductive Retaining Screw locks contacts in place
 - Large Raised Alignment Arrow aids in the mating of devices



Ordering Information

Description	Device Color	UPC	Catalog Number
150A, thermoplastic elastomer, cable size #8 - #2 AWG	Blue	783585458359	HBL15MBL

Standards

UL and cUL Listed
UL Enclosure Types 3R, 4X, 12
National Electric Code (NEC), ANSI/NFPA 70


Specifications

Base Compound	Thermoplastic Elastomer (TPE)
Contact Material	Brass
Retaining Screw Material	Nylon

Performance

Electrical	
Amperage Rating	150A Maximum
Voltage Ratings	600V AC Maximum; 250V DC Maximum

Mechanical	
Product Identification	Ratings are a permanent part of device
Terminal Accommodation	#8 to #2 AWG

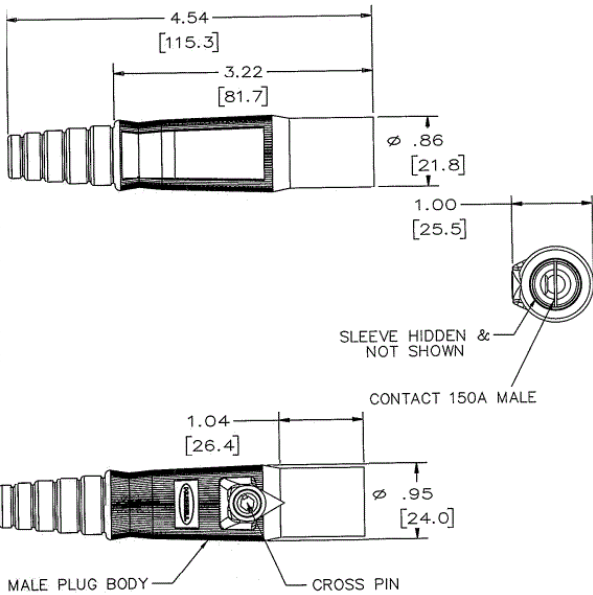

Online Resources

Customer Use Drawing
eCatalog
Installation Instructions

