



Item #
F828-BN/DW

Product Family Name:
Symbio

Category:
INTERIOR FAN

Certification
3129198

Patents:
U.S. Patent(s): D788,283; D788,286; D802,114

Notes:

UPC Code:
706411052651


Finish:
Brushed Nickel with Dark Walnut

Blades

Category Type:
Ceiling Fan



Image File Name: F828-BN/DW.jpg

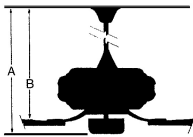

MEASUREMENTS

Blade Finish:		Reversible Blades:	
		No	
Blade Material:		Slope:	
ABS CONSTRUCTION		Yes	
Blade Sweep:	No. of Blades:	Blade Pitch:	Hanging Weight:
56"	5	15 DEGREES	15.98
Downrod 1:	Downrod 1 Outside	Downroad 2:	Downrod 2 Outside
6	Dia:		Dia:
	0.75		
Ceiling to Lowest	Ceiling to Blade	Lead Wire:	Motor Size:
Point: (Dim A)	(Dim B)	80"	DC/125x30
17.25	15.75		

	Low	Low/Med.	Medium	Med/High	High
RPM:	50				156
Amps:	0.076				0.552
Watts:	3.1				32.11
CFM:	1717.0				6276.0
CFM/Watts:	553.87				195.45



FAN CONTROLS

Pull Chain	Works with Remote Control:	Works with Wall Control:
Control:	Yes	Yes
No		
Reversible:	Included Remote Control:	Included Wall Control:
Yes	RC400	
	Compatible Remote	Compatible Wall Control(s):
	Control(s):	WC400

LAMPING

No. of Bulbs:	Light Type:			
1	LED			
Max Bulb	Socket:			
Wattage:	LED			
16				
Light Kit:	Dimmable:	Ballast:	Rated Life	Uplight:
Yes	Yes		Hours:	No
			30000	
Bulb/LED	Color Temp.:	CRI:	Initial Lumens:	Delivered
Included:	3000	82	1231.0	Lumens:
Yes				710.0

GLASS

Description:	Material:
Etched	GLASS
Part No.:	Quantity:
GF828	1
Width:	Length:



SHIPPING

Carton Width:	Carton Height:	Carton Length:
7.88	10.0	29.13
Carton Weight:	Carton Cubic Feet:	Small Package Shippable:
18.0	1.328	Yes
Master Pack Width:	Master Pack Height:	Master Pack Length:
Master Pack Weight:	Master Cubic Feet:	Multi-Pack:
		1

LED



LED

ETL
Intertek



WARNING: Handling this product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. Wash hands with soap and water after installing, handling, cleaning or otherwise touching this product. For more information go to: www.P65Warnings.ca.gov.

For additional information, please contact Customer Care: 1-800-221-7977 | Product depicted on this spec sheet is protected by United States Federal and/or State laws including US Patent, Trademark and/or Copyright and unfair competition laws. Unauthorized reproduction or use carries severe legal penalties.