

Color-Keyed®

Long Barrel Copper Lug

T&B Catalog Number:

54965BE

UPC Number:

78621089828

Status:

Active

Description:

Copper One-Hole Lug, Long Barrel, Blind End, Max 35kV, Wire Size 3/0 AWG, 1/2 Inch Bolt Size, Tin Plated, Die Code 50, Die Color Code Orange

General

Material	Copper
Finish	Tin Plated
Wire Size	3/0 AWG
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Orange
Die Code	50

Dimension Information

A (inches)	2.703
B (inches)	1.25
C (inches)	.922
D (inches)	.125
E (inches)	.625
F (inches)	.5

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging


T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	10.19 lbs. per 100

Application Support

T&B Instruction Sheets	ta01025-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

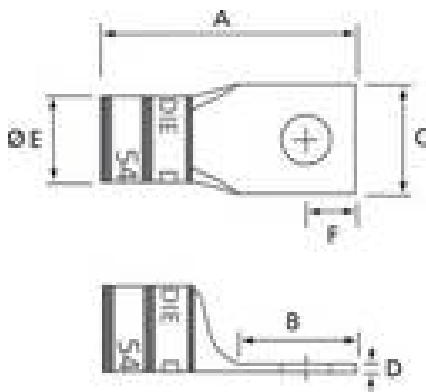

Certifications

RoHS Compliance Yes

Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com