




PRODUCT DESCRIPTION

Crown Hill is a traditional, early American style collection from Maxim Lighting International, available in multiple finishes.

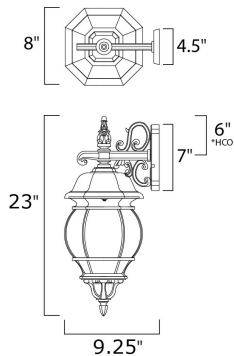

MEASUREMENTS

DIMENSION : 8" W x 23" H x 9.25" Ext
BACK PLATE : 4.5" W x 7" H x 6" HCO
HANGING WEIGHT : 6.6 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 2,016 Rated
BULB : 3 x 40W Incandescent E12 Candelabra , 120W Total
BULB INCLUDED : (Not Included)
DIMMABLE : Yes

FINISHES OPTION

- Black
- Pewter
- Rust Patina
- Taupe

GLASS

Clear CL

MATERIAL

Die Cast Aluminum

RATINGS

cETLus
Wet Location



ADDITIONAL

RATED LIFE 1500 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com