

Color-Keyed®

Long Barrel Copper Lug

T&B Catalog Number:

54878BE

UPC Number:

78621089810

Status:

Active

Description:

Copper Two-Hole Lug, Long Barrel, Blind End, Max 35kV, Wire Size 600 kcmil, 1/2 Inch Bolt Size, 1-3/4 Inch Hole Spacing, Tin Plated, Die Code 94, Die Color Code Green

General

Material	Copper
Finish	Tin Plated
Wire Size	600 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Green
Die Code	94

Dimension Information

A (inches)	5.75
B (inches)	2.984
C (inches)	1.75
D (inches)	.25
E (inches)	1.203
F (inches)	.5
G (inches)	1.75

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	6
Package in Units	60
T&B Sold in UOM	Each
T&B Weight Per UOM	78.5 lbs. per 100

Application Support


T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

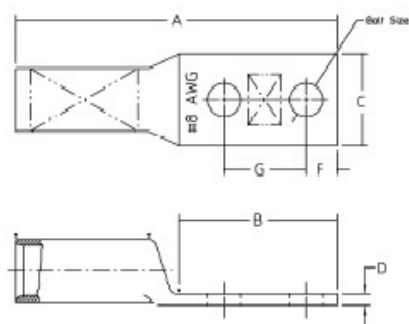

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com