

5334-I



UPC Code: 07847723340

Country Of Origin: Mexico

*Eligible for ARRA funded projects > \$7,443,000



5334-I

Brand Features

With Leviton's extensive assortment of combination devices, you can fill a one-gang space with two switches, a switch and receptacle, even a switch and GFCI. From sensor guide lights to multi-purpose styles and Tamper-Resistant receptacles, we accommodate your every need. These devices come in a range of colors and are backed by a limited two-year warranty. Built to last and designed to save space, these attractively styled devices are at home in any setting.

Item Description

20 Amp, 120/277 Volt, Duplex Style Single-Pole / Single-Pole AC Combination Switch, Commercial Grade, Non-Grounding, Side Wired, - Ivory

Technical Information

AC Horsepower Ratings

Max. Amperage: 16 Amp

HP Rating: 1HP-120V 2HP-240V-277V

Electrical Specifications

Dielectric Voltage: Withstands 1500V for 1 minute

Grounding: Non-Grounding

Switch Voltage: 120/277V AC

Overload UL20 Test: 100 cycles of OL at 4.8 times rated current

Temperature Rise: Maximum 30 degrees C rise

Switch Amperage: 20 Amp

Environmental Specifications

Operating Temperature: -40°C to 65°C

Flammability: Rated V-2 per UL94

Material Specifications

Strap Material: Steel

Body Material: Thermoplastic

Color: Ivory

Actuator Material: Thermoplastic

Mechanical Specifications

Product ID: Stamped on Strap

Terminal ID: Brass-Hot Black-Hot White-Neutral Green-Gnd

Termination: Side

Terminal Accom.: 14-12 AWG

Torque Range: 12-14 inch pounds

Product Features

Grounding: Non-Grounding

Warranty: 10-Year Limited

Color: Ivory

HP Rating: 1HP-120V 2HP-240V-277V

Standards and Certifications: UL

Standards and Certifications

CSA C22.2 No. 111: File #152105

Warranty: 10-Year Limited


UL Standard: UL 20

ANSI: C-73

NOM: 057

NEMA: WD-1 & WD-6

Dimensional Diagram

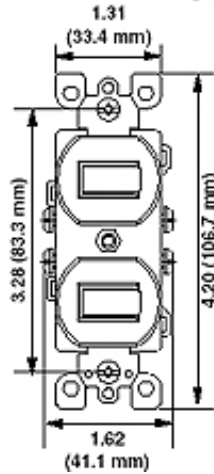

SPECIFICATION SUBMITTAL

JOB NAME: <input style="width: 95%; height: 20px;" type="text"/>	CATALOG NUMBERS: <input style="width: 95%; height: 20px;" type="text"/>	
JOB NUMBER: <input style="width: 95%; height: 20px;" type="text"/>	<input style="width: 95%; height: 20px;" type="text"/>	<input style="width: 95%; height: 20px;" type="text"/>

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Teléfono: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): +1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-

1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2012 Leviton Manufacturing Co., Inc. Todos los derechos reservados. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts/



**Leviton is the smart choice, providing the most comprehensive range of solutions to meet the needs of today's residential, commercial and industrial buildings. Leveraging more than a century of experience, Leviton helps customers create sustainable, intelligent environments through its electrical wiring devices, network and data center connectivity solutions, and lighting energy management systems. From switches and receptacles, to daylight harvesting controls, networking systems, and equipment for charging electric vehicles, Leviton solutions help customers achieve savings in energy, time and cost, all while enhancing safety.*