


# Surface Premium Wrap

## DIMENSIONS

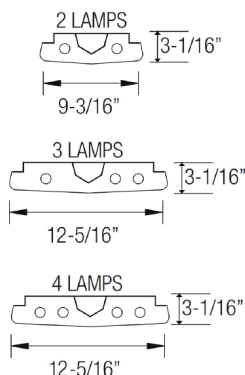

## APPLICATION

The SPW series is a specification grade wraparound fixture featuring an aesthetically appealing, low profile and functional design. The SPW utilizes a clear, extruded diffuser yielding low brightness glare free light. Use in closets, utility areas, hallways, kitchens, offices, and various residential and commercial applications.

## FEATURES

- Simple, functional and low profile design.
- Powder coated steel housings available in 2', 4', and 8' lengths.
- Utilizes T8 or T5 lamps in 2, 3, or 4 lamp configurations.
- Extruded clear acrylic diffuser composed of linear prisms on the side walls and evenly spaced pattern of conical prisms yielding low brightness, glare free light.
- Select 120V Ballasts are Energy Star qualified, FCC class B for residential and light commercial applications (consult factory for details)
- Lens can be hinged from either side in a lift & ship manner, for ease of re-lamping and cleaning.
- Can be wall mounted.
- NEC Required Ballast Disconnect is Standard on MV and HV Models.
- Nema Premium/CEE qualified ballast found standard on most fixture options (consult factory for details).

## ORDERING INFORMATION

SPW								
SERIES	SIZE	# OF LAMPS	LAMP TYPE	VOLTAGE	BALLAST TYPE	BALLAST FACTOR	OPTIONS	
	9 13	9" Housing 2-2 Lamps 2T- 2 Lamps Tandem (8" Fixture)  13" Housing 3-3 Lamps 4-4 Lamps	24" Housing 14- 14W T5 17- 17W T8 24- 24W T5HO  48" Housing 28- 28W T5 32- 32W T8 54- 54W T5HO	120- 120V  MV- 120-277V	(Blank)- Instant Start*  PS- Programmed Start	(Blank)- Normal  H- High  L- Low	EM5- 450 Lumen Battery Backup EM7- 700 Lumen Battery Backup EM14- 1400 Lumen Battery Backup EM30- 3000 Lumen Battery Backup OS- Occupancy Sensor	T8 and T5 lamps (all color temps. available)

## ACCESSORIES