



Color:  Gray

UPC Code: 078477723722

Country Of Origin: China

NEMA:
5-20R



GFTR2-HGG

Self-Test SmartlockPro GFCI Duplex Receptacle Outlet, Extra Heavy-Duty Hospital Grade, Wallplate Included, Tamper-Resistant, Power Indication, 20 Amp, 125 Volt, Back or Side Wire, NEMA 5-20R, 2-Pole, 3-Wire, Self-Grounding - Gray

Technical Information

AC Horsepower Ratings

At Rated Voltage: 1 HP

Electrical Specifications

Amperage: 20 A

Grounding: Self-Grounding

Pole: 2

Short Circuit Current Rating: 10kA

Voltage: 125 VAC

Wire: 3

Environmental Specifications

Flammability: Rated V-0 per UL 94

Operating Temperature: -35C to +66C

Material Specifications

Body Material: Polycarbonate

Face Material: PBT

Ground Clips: Brass

Grounding Screw: Plated Steel

Line Contacts: Brass

Shutter Mechanism: Delrin® Acetal

Strap Material: Galvanized Steel

Terminal Clamp: Brass

Terminal Screws: Plated Steel

Mechanical Specifications

Product ID: Ratings are permanently marked on device

Terminal Accom.: 14-10 AWG solid or stranded

Terminal ID: Brass-Hot, Green-Ground, Silver-Neutral

Termination: Back or Side Wire

Product Features

Brand: SmartlockPro

Color: Gray

Device Type: Duplex Receptacle Outlet

Feature: Wallplate Included, Tamper-Resistant, Power Indication, Self-Test

Function: GFCI

Grade: Extra Heavy-Duty Hospital Grade

NEMA: 5-20R

Standards and Certifications

ANSI: C-73

Applicable Standards: UL 943, UL 498, CSA C22.2 No. 42 & 144, FedSpec W-C-596

Certification/Listing: UL, CSA, NOM-ANCE

NEMA: WD-1 & WD-6


Warranty

Product Warranty: 2-Year Limited

Patents*

CA2341552	US7355117
CA2358721	US7400479
CA2425810	US7697252
CA2427366	US7737809
CA2515035	US7764151
CA2621644	US7820909
CA2677283	US7868719
MX234458	US8004804
MX251584	US8242362
MX269232	US8547126
MX276411	US8587914
MX276626	US8599522
MX302458	US9053886
MX308495	US9077091
MX315596	

*This list is provided for patent marking purposes only. A good faith effort is made to maintain the accuracy and completeness of this list. No legal inference should be drawn from the omission of a patent from this list.

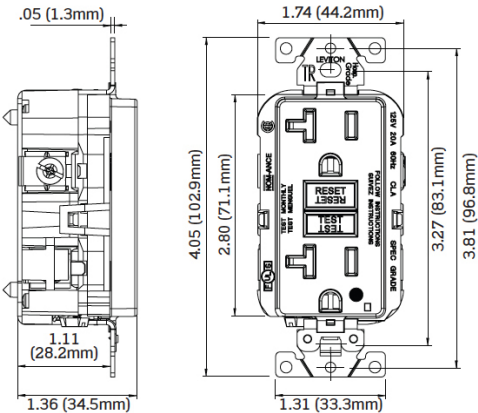

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):
+1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·
FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-
1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:
www.leviton.com/international/contacts/

