

Watertight Devices
Accessories
Portable Outlet Box Covers



Features

- Impact and heat resistant PBT housing
- Corrosion-resistant stainless steel springs and hinges
- Gasketed to maintain UL Type 3R

Ordering Information

Description	Device Color	UPC	Catalog Number
Outlet box lift cover; GFCI.	Gray	783585358901	HBL3060

Listings


Listed to UL514D
UL Type 3R
Meets NEMA WD-1, WD-6 and ANSI standards

Specifications

Housing	PBT
Cover plate screws	Stainless steel
Cover plate spring	Stainless steel
Hinge Pin	Stainless steel
Hinge bracket	Stainless steel
Gasket	Neoprene

Performance

Environmental	
Flammability	UL94 V-0
Moisture Resistance	UL Type 3R
Operating temperatures	-40°C (without impact) to +60°C continuous
UV Resistance	All exposed materials are UV stabilized

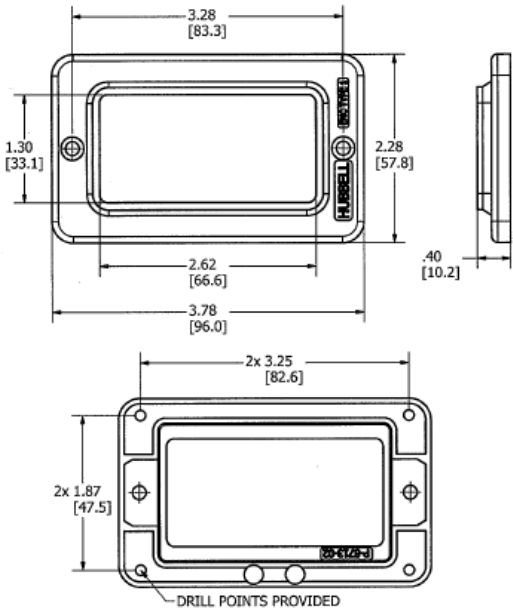

Online Resources

[eCatalog](#)

