



A-Shape LED

9A19/LED/830/DIM 120V 6/1

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

General Information			
Cap-Base	E26 [Single Contact Medium Screw]	Starting Time (Nom)	0.5 s
Bulb Shape	A19 (A19)	Warm Up Time To 60% Light (Nom)	0.5 s
Nominal Lifetime (Nom)	25000 h	Power Factor (Nom)	0.7
Switching Cycle	50000X	Voltage (Nom)	120 V
Technical Type	9-60W		
		Temperature	
		T-Case Maximum (Nom)	95 °C
		Controls and Dimming	
		Dimmable	Yes
		Mechanical and Housing	
		Bulb Finish	Frosted (FR)
		Approval and Application	
		Suitable For Accent Lighting	Yes
		Product Data	
		Order product name	9A19/LED/830 DIM 120V
		EAN/UPC - Product	046677459055
		Order code	459057
		Numerator - Quantity Per Pack	1
		Numerator - Packs per outer box	6


Light Technical	
Color Code	830 [CCT of 3000K]
Initial lumen (Nom)	800 lm
Luminous Flux (Rated) (Nom)	800 lm
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	88.88 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	9 W
Lamp Current (Nom)	100 mA
Wattage Equivalent	60 W

A-Shape LED

Material Nr. (12NC)	929001196904
Net Weight (Piece)	0.084 kg

Dimensional drawing

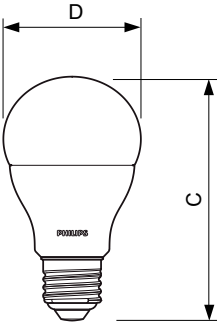


Bulb A19 120V 9W-60W 800lm 300D 3000K

Product	D	C
9A19/LED/830 DIM 120V	61.4 mm	109.8 mm

Photometric data

General Uniform Lighting

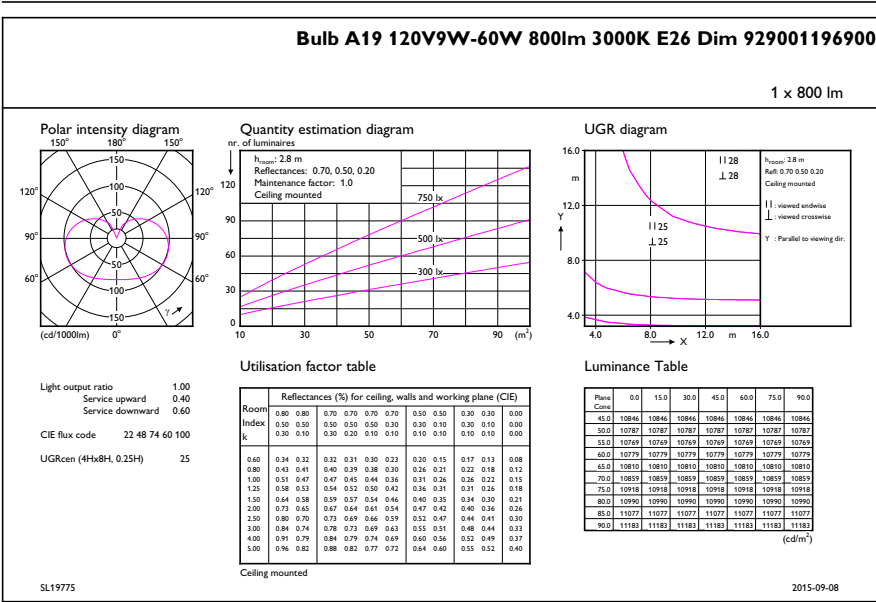

A-Shape LED

