


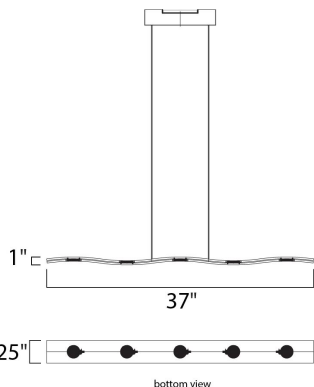

Measurements:

<u>Height</u>	<u>Width</u>	<u>Length</u>	
1.00"	4.75"	37.00"	
<u>Max OAH</u>	<u>Min OAH</u>		
121.00"	4.75"		
<u>Hanging Weight</u>	<u>Canopy Width</u>	<u>Canopy Height</u>	<u>Canopy Length</u>
4.90 lb	4.75"	2.25"	9.75"

Lamping:

LED PCB LED	1,750 Rated Lumens
1 25W PCB LED	3000 Color Temperature
25 total watt	80+ CRI
Dimmable : Standard Triac/Lutron® or Leviton® CL	

Shipping:

<u>Carton Weight</u>	<u>Carton Width</u>	<u>Carton Height</u>	<u>Carton Length</u>
8.40 lb	5.50"	4.30"	50.20"
<u>Master Pack Qty</u>	<u>UPC</u>	<u>UPS</u>	
1.0000	845094075509	Yes	

Finish:
Matte White MW

Material:
Aluminum

Certification:
Dry Location

Additional:
PCB LED (Included)
Adjustable