

CS6370

50Amp, 125V AC, Non-NEMA, 2P, 3W, Black & White Locking Flush Mount Receptacle, Industrial Grade, Grounding, California-Style(CS) – BLACK



Color:  Black

UPC Code: 07847732603

Country Of Origin: Mexico

NEMA:
Non-NEMA



Leviton's Industrial Grade Locking Devices are built to provide unparalleled quality and superior performance in the most severe industrial settings. Leviton combines the best materials available with superior production standards to produce a broad selection of Locking Devices of unmatched flexibility and dependability.

Technical Information

Electrical Specifications

Grounding: Grounding

Amperage: 50 A

Voltage: 125 VAC

Pole: 2

Wire: 3

Dielectric Voltage Withstand: 2000V minimum per UL 498

Maximum Working Voltage: 125V as rated

Current Interrupting: Certified for current interrupting at full rated current

Temperature Rise: Max 30°C temp rise at full-rated current after 150 cycles of OL at 150% rated DC current

Environmental Specifications

Flammability: Rated V-0 per UL 94

Operating Temperature: -40°C to 75°C

Environment: Dry

Material Specifications

Face Module: Reinforced Nylon

Body & Contract Carrier: Reinforced Nylon

Shroud: .062inch thick Nickel Plated Steel

Back Cover: Reinforced Nylon

Mounting Strap: Single piece SS 302/304

Mounting Screws: SS 302/304

Assembly Rivets: SS 302/304

Center Pin: SS 302/304

Connector Contact - Spring: 0.041inch thick Brass

Connector Contact - Binding Plate: 0.100inch thick Brass

Contact Rivet: Brass

Box Terminal: 0.062inch thick Copper

Terminal Set Screw: SS 302/304

Color: Black

Mechanical Specifications

Terminal ID: X, W, Y, Z and Green for ground

Terminal Accom.: #10min to #6max AWG Solid or Stranded Wire (Stranded Wire for Ground only)

Product ID: Ratings and Catalogue No. molded into face

Product Features

NEMA: Non-NEMA

Color: Black

Device Type: Locking Receptacle

Brand: Black and White

Standards and Certifications


UL 498: File E13399

CSA C22.2 No. 42: File 152105

NOM: 057

RoHS: Compliant

Warranty: Lifetime Limited

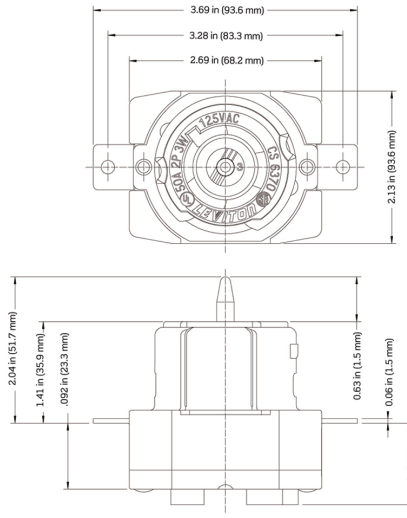

SPECIFICATION SUBMITTAL

JOB NAME: JOB NUMBER:	CATALOG NUMBERS:
---	---

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):
+1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·
FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-
1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:
www.leviton.com/international/contacts/

