

LOW - VOLTAGE P E N D A N T S

Pelé Pendant

DESCRIPTION

Modern glass sphere topped with glass detail. Includes low-voltage, 50 watt frosted halogen bi-pin lamp or 8 watt replaceable 500 lumen 80 CRI 3000K LED SORAA® module and six feet of field-cutttable suspension cable. Works with SORAA.

INSTALLATION


Socket terminates with FreeJack male connector, which may be installed into a system connector. Elements ordered with a system prefix include a connector for that system.

ACCESSORIES & OPTICAL CONTROLS

SORAA® LED Bi-Pin Replacement Pendant Module

WEIGHT

1.19lb / 0.54kg ±

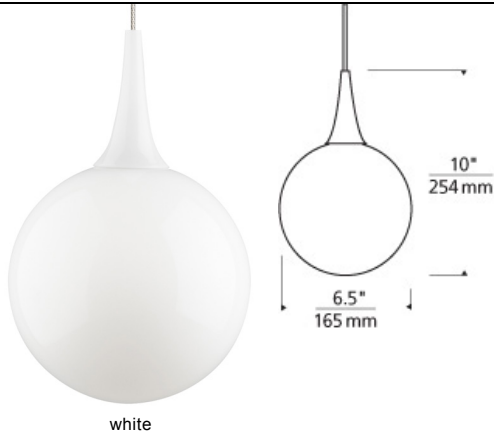

white



white

ORDERING INFORMATION

700	SYSTEM	PEL	COLOR	FINISH	LAMP
FJ	FREEJACK		W WHITE	Z ANTIQUE BRONZE	12 VOLT HALOGEN
KL	KABLE LITE			C CHROME	-LEDS830 12 VOLT LED 80 CRI 3000K
MP	MONOPOINT			S SATIN NICKEL	-24 24 VOLT HALOGEN
MO	MONORAIL				
MO2	TWO-CIRCUIT MONORAIL				

Note: Note: MP includes 4" Round Flush Canopy.

Antique Bronze is not available for Kable Lite.

Chrome not offered on Monorail & Two~Circuit Monorail.

When installing LED option on MO2 only magnetic transformers may be used.



TECH LIGHTING®
 7400 Linder Avenue T 847.410.4400
 Skokie, Illinois 60077 F 847.410.4500
Tech Lighting, L.L.C.

700 ____ PEL ____

FIXTURE TYPE: _____

JOB NAME: _____

NOTES: _____
