



Candle/Decorative LED

4.5B12/LED/827-22/E26/DIM120V

Philips Candle Dimmable LED Lamps offer decorative energy saving ambience with the elegant effect of incandescent candles. Available in bent, blunt and flame tip candles, their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

Product data


General Information		Starting Time (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]	Warm Up Time To 60% Light (Nom)	0.5 s
Bulb Shape	B12	Power Factor (Nom)	instant full light
Nominal Lifetime (Nom)	25000 h	Voltage (Nom)	0.7
Switching Cycle	50000X		120 V
Technical Type	4.5-40W	Temperature	
Light Technical		T-Case Maximum (Nom)	100 °C
Color Code	822-827 [tunable warm white]	Controls and Dimming	
Initial lumen (Nom)	330 lm	Dimmable	Yes
Luminous Flux (Rated) (Nom)	330 lm	Mechanical and Housing	
Color Designation	Warm White (WW)	Bulb Finish	Clear (CL)
Correlated Color Temperature (Nom)	2200-2700 K	Approval and Application	
Color Consistency	ANSI 2700K	Suitable For Accent Lighting	No
Color Rendering Index (Nom)	80	Energy Efficiency Label (EEL)	Not applicable
LLMF At End Of Nominal Lifetime (Nom)	70 %	Energy Consumption kWh/1000 h	4.5 kWh
Operating and Electrical		Product Data	
Input Frequency	60 Hz	Order product name	4.5B12/LED/827-22/E26/DIM120V
Power (Rated) (Nom)	4.5 W	EAN/UPC - Product	046677457198
Lamp Current (Nom)	45 mA		
Wattage Equivalent	40 W		

Candle/Decorative LED

Order code	457192
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001167304

Net Weight (Piece)	0.072 kg
--------------------	----------

Dimensional drawing

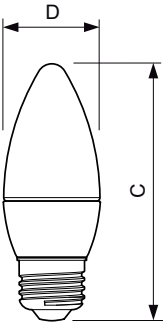

LED 4.5-40W E26 B12 CL DIM

Product	D	C
4.5B12/LED/827-22/E26/DIM120V	38 mm	110 mm

