

PAR38 17W DIM. TITANIUM CRI^{SP} LED SERIES 4.0



CRI^{SP}



17W REPLACES



120W
Hal.

80% Energy Savings

\$331 Savings
per lamp*

- Full-face REFINE optic and sleek design
- Exceptional color rendering CRI 90
- Richer reds and natural skin tones (R9 50, R13 90)
- Tight LED binning for consistent CCT across all lamps
- Suitable for use in totally enclosed fixtures
- Wet location rated for outdoor use



LM 79

LM 80

TM 21



40,000 H



DIMMABLE



WET
LOCATION



WARRANTY



CRI (Ra)



ENCLOSED**

PATENT PENDING REFINE OPTIC

The innovative REFINE optic provides a high candela to lumen ratio, optimizing light usage for directional applications.



REFLECTOR
Directs light



FOCUS LENS
Focuses center beam

SHAPING LENS
Refines beam pattern



 
WATCH THE VIDEO

PAR38 17W DIM. TITANIUM CRI^{SP} LED SERIES 4.0




ILLUMINANCE & CANDELA DISTRIBUTION

18.5PAR38G4DIM/930SP15




Diameter	Footcandles
0.8	1222
1.6	306
2.4	136
3.2	76
3.9	49

18.5PAR38G4DIM/930NF25

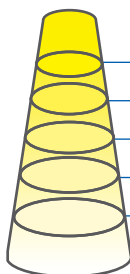


Diameter	Footcandles
1.3	656
2.7	164
4	73
5.3	41
6.7	26


17PAR38G4DIM/930FL40

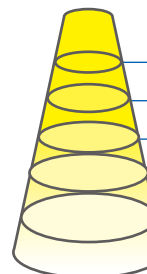


Diameter	Footcandles
2.2	278
4.4	69
6.6	31
8.7	17
10.9	11

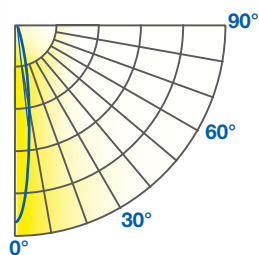

Degree	Candela
0	11,000
5	6028
15	835
25	188
35	111
45	83

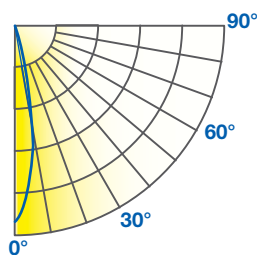


Degree	Candela
0	5900
5	5326
15	156
25	321
35	116
45	92

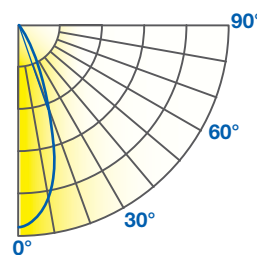

Degree	Candela
0	2500
5	2329
15	1489
25	381
35	143
45	74

For other CCT use the following multipliers: 2700K .95, 4000K 1.1

Base: E26
Voltage: 120V
Dimmable: Yes***
PF: 0.9
Lifetime: 40,000 hrs
Weight: 0.75lb / 340g

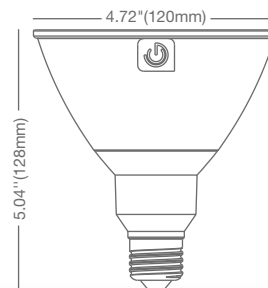

SPECIFICATIONS

Model	Product	Power (W)	CCT	CRI (typ.)	R9 / R13 (typ.)	Lumens	LPW	Beam Angle	CBCP (cd)
18.5PAR38G4DIM/927SP15	16147	18.5	Warm White 2700K	90	50 / 90	950	51	SP 15°	10,500
18.5PAR38G4DIM/927NF25	16148	18.5	Warm White 2700K	90	50 / 90	1105	60	NF 25°	5800
17PAR38G4DIM/927FL40	16149	17	Warm White 2700K	90	50 / 90	1105	65	FL 40°	2400
18.5PAR38G4DIM/930SP15	16150	18.5	Warm White 3000K	90	50 / 90	1000	54	SP 15°	11,000
18.5PAR38G4DIM/930NF25	16151	18.5	Warm White 3000K	90	50 / 90	1150	62	NF 25°	5900
17PAR38G4DIM/930FL40	16152	17	Warm White 3000K	90	50 / 90	1150	68	FL 40°	2500
17PAR38G4DIM/940FL40	16155	17	Natural White 4000K	90	50 / 90	1200	71	FL 40°	2650
18.5PAR38G4DIM/930SP15/B •	16256	18.5	Warm White 3000K	90	50 / 90	1000	54	SP 15°	11,000
18.5PAR38G4DIM/930NF25/B •	16257	18.5	Warm White 3000K	90	50 / 90	1150	62	NF 25°	5900
17PAR38G4DIM/930FL40/B •	16258	17	Warm White 3000K	90	50 / 90	1150	68	FL 40°	2500

• Black finish

* Savings per lamp based on \$0.11 / kw energy cost, 12 hrs / day lamp usage, \$8

halogen with 1500-hr lifetime, \$32 LED with 40,000-hr lifetime

** Suitable for use in totally enclosed fixtures

*** List of tested dimmer switches available on website

**** Suitable for wet locations