



AIM, Black - Specification Sheet
by Ronan and Erwan Bouroullec, 2013

Mounting	Ceiling Pendant
Lamp (Bulb) Description	1 x LED 2700K 1250lm CRI 90 - 20W
Environment	Indoor - Dry Location
Dimming	Dimmable
Finish	Black
Technical and Product Description	The AIM ceiling light was designed by the Bouroullec brothers in 2010.

The AIM is a form of modern pendant lighting that is constructed from a varnished aluminum sheet with a photo-etched optical polycarbonate shade and an internal reflector of a photo-etched ABS. The cable can be adjusted to allow the fixture head and light distribution to be aimed. The cable has a total length of 29 ft 5 inches (9m) allowing the lamp to be suspended up to 9 ft 8 inches (3m) from the ceiling.

The AIM emits direct lighting. The minimalist pendant lamp has two versions and is available in black or white. Please select model of choice when ordering.

1. AIM - Hardwired: Connects to wall-switch by hardwiring to a 120V junction box (no additional LED driver is required). Comes with a 5" diameter canopy.
2. AIM - Plug-in: Switch and cord that you can plug into a socket (NOT dimmable)

NOTE: We offer discounts on the purchase of 3 or more AIM HARDWIRE fixtures. Discounted pricing will show in shopping cart at checkout. If multiple fixtures are to be hardwired to a single junction box, you must purchase a special canopy other than the one that is included. This canopy will allow 3-5 pendants to be hardwired to one junction box (this does not apply to plug-in version).

Please contact customer service by sending an email to e-shop@flosusa.com or by calling toll-free 844.FLOS.USA for details.

Inspiration behind the design:

Ronan and Erwan Bouroullec wanted to keep the core essence of the lamp they created limited to the source of light and its cord. The AIM ceiling light does just that and therefore appeals to any kind of setting it is placed in not only because of its shape but also because it is designed to conveniently "aim" light at specific locations.

Electrical

Voltage	120
Switching	Dimmable with Leading Edge (Triac) dimmers
IP Rating	IP20


Physical

Cord Length (inches)	354" - Black
Construction Material	Aluminum, Polycarbonate
Weight	7.1 lbs



● FU009030 Black

Dimensional Image

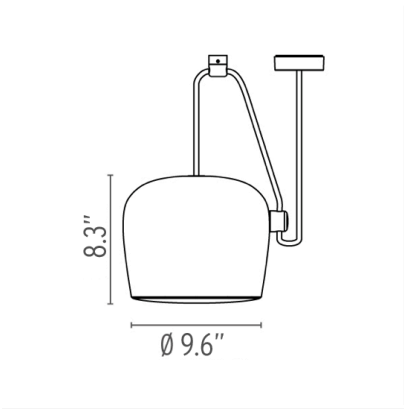

Certifications

