



# Candle/Decorative LED

## 7B12/LED/827-22/E12/DIM 120V

Philips Candle Dimmable LED Lamps offer decorative energy saving ambience with the elegant effect of incandescent candles. Available in bent, blunt and flame tip candles, their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

### Product data


General Information		Starting Time (Nom)	
Cap-Base	E12 [ Candelabra Screw]		0.5 s
Bulb Shape	B12	Warm Up Time To 60% Light (Nom)	instant full light
Nominal Lifetime (Nom)	25000 h	Power Factor (Nom)	0.9
Switching Cycle	50000X	Voltage (Nom)	120 V
Technical Type	7-60W		
Light Technical		Temperature	
Color Code	822-827 [ tunable warm white]	T-Case Maximum (Nom)	100 °C
Initial lumen (Nom)	500 lm		
Luminous Flux (Rated) (Nom)	500 lm	Controls and Dimming	
Color Designation	Warm White (WW)	Dimmable	Yes
Correlated Color Temperature (Nom)	2200-2700 K		
Color Consistency	ANSI 2700K	Mechanical and Housing	
Color Rendering Index (Nom)	80	Bulb Finish	Clear (CL)
LLMF At End Of Nominal Lifetime (Nom)	70 %		
Operating and Electrical		Approval and Application	
Input Frequency	60 Hz	Suitable For Accent Lighting	No
Power (Rated) (Nom)	7 W	Energy Efficiency Label (EEL)	Not applicable
Lamp Current (Nom)	65 mA	Energy Consumption kWh/1000 h	7 kWh
Wattage Equivalent	60 W		
		Product Data	
		Order product name	7B12/LED/827-22/E12/DIM 120V
		EAN/UPC - Product	046677458690

## Candle/Decorative LED

Order code	458695
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001182004

Net Weight (Piece)	0.063 kg
--------------------	----------

### Dimensional drawing

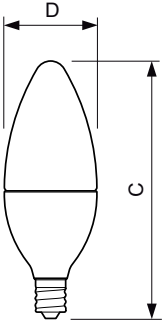

LED 7-60W E12 B12 CL DIM

Product	D	C
7B12/LED/827-22/E12/DIM 120V	38 mm	114 mm

