


CYLO – model: WS-W20

LED Outdoor Sconce Luminaire

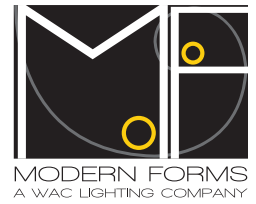


Fixture Type:

Catalog Number:

Project: _____

Location: _____

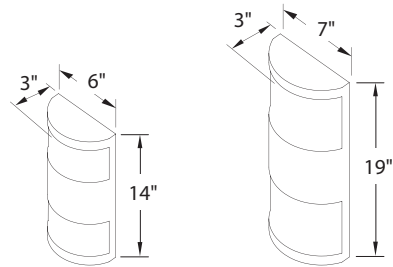

PRODUCT DESCRIPTION

A decorative half cylinder wall sconce that delivers excellent visibility at night and adds appeal to building facades. Cylo is a simple modern design to meet a broad scope of design requirements.

FEATURES

- ETL & cETL listed for wet locations
- Low profile design
- Interior light and down light
- Replaceable LED module
- 60,000 hour potential life
- 130° beam angle
- **Color Temp: 3000K**
- **CRI: 90**

SPECIFICATIONS

Construction: Aluminum with etched opal glass.

Power: Transformer located in outlet box. 120V input.

Light Source: High output LED.

Dimming: Dims to 10% with an electronic low voltage (ELV) dimmer.

Mounting: Mounts directly to junction box.

Finish: Bronze (BZ).

Standards: ETL & cETL listed. ADA compliant.

Installation: Requires Transformer to be recessed within the junction box.

ORDER NUMBER

Model	Height		Watt	# of LEDs	LED Lumens	Photometric Lumens	Finish
	14"	19"					
WS-W20	14"	19"	22W	48	1252	285	BZ Bronze
	19"	19"	32W	72	1878	495	

REPLACEMENT GLASS

Model	Fixture	Description
RPL-GLA-2014-01	WS-W2014	Main Body
RPL-GLA-2014-02		Bottom Lens
RPL-GLA-2019-01	WS-W2019	Main Body
RPL-GLA-2019-02		Bottom Lens

WS-W20 -

Example: **WS-W2014-BZ**

modernforms.com
Phone (800) 526.2588
Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive
Port Washington, NY 11050

Central Distribution Center
1600 Distribution Ct
Lithia Springs, GA 30122

Western Distribution Center
1750 Archibald Avenue
Ontario, CA 91760