



Candle/Decorative LED

7B12/LED/827-22/E26/DIM 120V

Philips Candle Dimmable LED Lamps offer decorative energy saving ambience with the elegant effect of incandescent candles. Available in bent, blunt and flame tip candles, their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

Product data


General Information			
Cap-Base	E26 [Single Contact Medium Screw]	Starting Time (Nom)	0.5 s
Bulb Shape	B12	Warm Up Time To 60% Light (Nom)	instant full light
Nominal Lifetime (Nom)	25000 h	Power Factor (Nom)	0.9
Switching Cycle	50000X	Voltage (Nom)	120 V
Technical Type	7-60W	Temperature	
Light Technical		T-Case Maximum (Nom)	100 °C
Color Code	822-827 [tunable warm white]	Controls and Dimming	
Initial lumen (Nom)	500 lm	Dimmable	Yes
Luminous Flux (Rated) (Nom)	500 lm	Mechanical and Housing	
Color Designation	Warm White (WW)	Bulb Finish	Clear (CL)
Correlated Color Temperature (Nom)	2200-2700 K	Approval and Application	
Color Consistency	ANSI 2700K	Suitable For Accent Lighting	No
Color Rendering Index (Nom)	80	Energy Efficiency Label (EEL)	Not applicable
LLMF At End Of Nominal Lifetime (Nom)	70 %	Energy Consumption kWh/1000 h	7 kWh
Operating and Electrical		Product Data	
Input Frequency	60 Hz	Order product name	7B12/LED/827-22/E26/DIM 120V
Power (Rated) (Nom)	7 W	EAN/UPC - Product	046677458669
Lamp Current (Nom)	65 mA		
Wattage Equivalent	60 W		

Candle/Decorative LED

Order code	458661
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001182104

Net Weight (Piece)	0.072 kg
--------------------	----------

Dimensional drawing

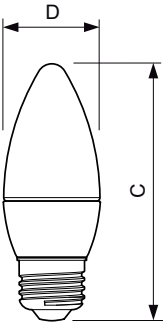

LED 7-60W E26 B12 CL DIM

Product	D	C
7B12/LED/827-22/E26/DIM 120V	38 mm	110 mm

