



Halogen Deco

Halogen BC40G16.5/EV/CL 120V 6/2 TP

Halogen bulbs reduce energy consumption without sacrificing the qualities of a traditional bulb. They uniquely produce light more efficiently. They work with dimmer switches and are available in the familiar G25 & G16.5 globes, bent and blunt tip candles, and flames. Use them in existing fixtures just as you would standard incandescents and your home will look great while you save energy.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Main Application	Eco Vantage
Gas Filling	Gas
Light Technical	
Luminous Flux (Nom)	540 lm
Luminous Flux Lamp @ 120V	540 lm
Correlated Color Temperature (Nom)	2800 K
Color Rendering Index (Nom)	100
Operating and Electrical	
Power (Rated) (Nom)	40 W
Lamp Wattage Rated@120V	40 W
Voltage (Nom)	120 V

Mechanical and Housing	
Bulb Finish	Clear
Cap-Base Information	Brass Cap
Product Data	
Order product name	Halogen BC40G16.5/EV/CL 120V 6/2 TP
EAN/UPC - Product	50046677433562
Order code	925719136301
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	925719136301
Net Weight (Piece)	0.020 kg

Halogen Deco

Dimensional drawing

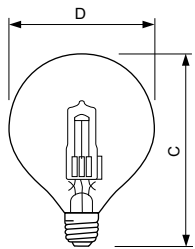

Product	D	C (max)
Halogen BC40G16.5/EV/CL 120V 6/2 TP	2 in	2.96 in

40W E26 120V G16.5 CL

